


Distanzhalter LCS / LCBS

- Material:** Polyamid 6.6, natur / RMS-01 UL 94 V-2 E70062
bzw. Polyamid 6.6, natur / RMS-19 UL 94 V-0 E70062

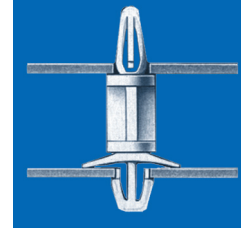


Werk-Bezeichnung	LCS	LCS	LCBS	LCBS	LCBS-2	LCBS-6	LCBS-8
Leiterplattendicke	1,2 - 1,7	1,2 - 1,7	1,6	1,6	1,6	2,4	1,6
Leiterplattenbohrung	4,0	4,0	4,0	4,0	4,0	4,0	4,0
Trägerplattendicke	0,8 - 2,0	0,8 - 2,0	0,8 - 2,0	0,8 - 2,0	2,0 - 3,6	2,0 - 3,6	0,2 - 1,4
Trägerplattenbohrung	4,8	4,8	4,8	4,8	4,8	4,8	4,8
Durchmesser	6,0	6,0	7,1	7,1	7,1	7,1	7,1
Brennbarkeitsklasse	UL94V-2	UL94V-0	UL94V-2	UL94V-0	UL94V-2	UL94V-2	UL94V-2


Länge A

in mm	in Zoll	Bestell-Nr.						
3,5	3/16"	6.02.036	6.02.037					
4,8	3/16"	6.02.046		6.35.046	6.35.047	6.38.216	6.38.604	6.38.804
6,4	1/4"	6.02.066		6.35.066	6.35.067	6.38.226		6.38.806
7,9	5/16"	6.02.076	6.02.077	6.35.076	6.35.077		6.38.607	6.38.807
9,5	3/8"	6.02.096	6.02.097	6.35.096	6.35.097	6.38.246	6.38.609	6.38.809
11,1	7/16"	6.02.116	6.02.117	6.35.116	6.35.117			6.38.811
12,7	1/2"	6.02.126	6.02.127	6.35.126	6.35.127	6.38.266		6.38.812
15,9	5/8"	6.02.156	6.02.157	6.35.156	6.35.157	6.38.286	6.38.615	6.38.815
19,1	3/4"	6.02.196	6.02.197	6.35.196	6.35.197	6.38.292	6.38.619	6.38.819
22,2	7/8"	6.02.226	6.02.227	6.35.226	6.35.227	6.38.293	6.38.622	6.38.822
25,4	1"	6.02.256	6.02.257	6.35.256	6.35.257	6.38.294	6.38.625	6.38.825
28,6	9/8"	6.02.286	6.02.287	6.35.286	6.35.287	6.38.295	6.38.628	6.38.828
31,7	5/4"	6.02.316	6.02.317	6.35.316	6.35.317	6.38.298	6.38.631	6.38.831
34,9	11/8"	6.02.346	6.02.347	6.35.346	6.35.347	6.38.299		6.38.835


	LCS	LCS	LCBS-xM				
	UL94V-2	UL94V-0	UL94V-2				
6,0	6.12.066	6.12.067	6.38.106				
8,0	6.12.086	6.12.087	6.38.108				
10,0	6.12.106	6.12.107	6.38.110				
12,0	6.12.126	6.12.127	6.38.112				
14,0	6.12.146	6.12.147	6.38.114				
16,0	6.12.166	6.12.167	6.38.116				
20,0	6.12.206	6.12.207					
24,0	6.12.246	6.12.247					

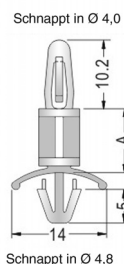

LCS

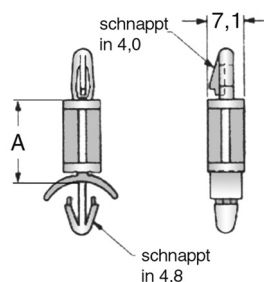

LCBS-2

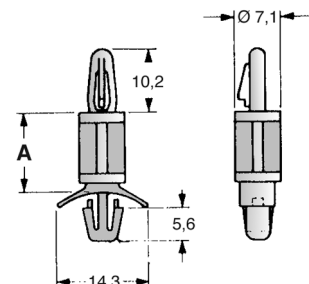

LCBS, -6; -8;-M