


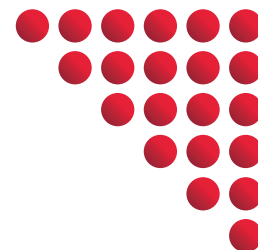

Compact portable printer

Ap1310 series

With extra paper/label roll capacity



Design registered

Unique SINGLE-handed easy paper-load system

No other printer is easier!

Typical applications include:

POS
Healthcare
Retail
Leisure Hospitality
Data Logging
In-vehicle

POWERFUL YET COMPACT

- 38 meters of print per paper/label roll reducing paper changes and minimising maintenance for operational efficiencies
- Bluetooth® compatible for flexible use with all smart phones and tablets for a truly connected business
- Utilising a high speed and high quality fixed head thermal mechanism with superb quality text and graphics
- Linerless labels save precious time & reduce waste
- Intelligent battery management for optimal efficiency
- Robust yet compact design with the flexibility for both portable printing and wall mounting

YOUR LOCAL DISTRIBUTOR:

able

Head Office

(Design, Sales, Technical Support
and Repairs)

Able Systems Limited
Denton Drive
Northwich
Cheshire
CW9 7TU
England

Tel: +44 (0) 1606 48621

Fax: +44 (0) 1606 44903

Visit:

www.able-systems.com



www.able-systems.com

Compact portable printer Ap1310 series
DATASHEET



Compact portable printer

Ap1310 series

With extra paper/label roll capacity



| Specification | Ap1310 | Ap1310BT |
|-------------------------------|--|---|
| Data Input | RS-232 Serial (RJ12 connector) | RS-232 Serial (RJ12 connector) |
| Wireless Data Input | N/A | Bluetooth V2.1 (Profiles: LM, L2CAP, RFCOMM, SDP, TCS, SSP and IAP. OPP optional) |
| Print Method | Fujitsu fixed head thermal mechanism | |
| Print Speed | 60 mm/s (at 7.2V battery voltage); 50mm/s (typical) | |
| Paper Specification | Paper Roll Width: 57.0 ± 0.5mm. Max roll diameter: 55mm (typical length 37.7m). Paper roll A05856TPR1 | |
| Print Width | 48 mm | |
| Dots Per Line (Graphics) | 384 | |
| Dot Spacing | 8 dots/mm (vertical and horizontal) | |
| Sensors | Paper Out (Opto reflective) and Head Up (Mechanical) | |
| Data Buffer | 20 Kb | |
| Baud Rate | Up to 57,600 (9600 Default) | |
| Character Set | CP1252 and CP437 supplied as standard. Range of popular Code Pages available with up to 6 resident simultaneously (See note 1) | |
| Number Of Columns | 12, 16, 21, 24, 42, 32 (Default). (See note 1) | |
| Font (Dots) | 7 x 24, 10 x 24 (Default). (See note 1) | |
| Dimensions | 65 x 95 x 128 mm (H x W x L) | |
| Weight | 446g (including battery and full roll of paper) | |
| Power Supply Options | As standard the Ap1310 range is supplied with a shrink-wrapped re-chargeable battery pack (5 cell 6V NiMH), together with an adapter to allow the use of primary cells. Note that chargers and data or power cables need to be ordered separately (see below) or as part of a complete kit. Power supply options include: <ul style="list-style-type: none">BC1300: Universal i/p trickle chargerBC1300CLAHL: 12V/24V vehicle trickle charger | |
| Accessories | <ul style="list-style-type: none">Ap1300BR01: Combined wall mounting bracket and belt clipAp1300D9: D9 to RJ12 data cable (with jack socket for alternative charging)Ap1300BP01: Spare NiMH battery pack | |
| Connectivity | Drivers available for Windows & Linux. Android & IOS demo apps and SDK also available. Download from www.able-systems.com | |
| Temperature Range (Operating) | 0 - 50°C | |
| Reliability - MCBF | 10 ⁸ print pulses or 50kms. >13 million print lines (Approx. 3,500 paper rolls). | |

Note 1: The proprietary Font Editor Utility software (order code Ap800FEU) enables customisation of character fonts by the user.

Kits

All items available individually or as part of the below kits:

| | Ap1310 Printer | Ap1310BT Printer | Universal Trickle Charger | D9 Data Cable | Belt Clip / Mounting Bracket | 2 Paper Rolls | Primary Cell Cradle | Bluetooth |
|--------------|----------------|------------------|---------------------------|---------------|------------------------------|---------------|---------------------|-----------|
| Ap1310KIT1 | ✓ | | ✓ | ✓ | ✓ | ✓ | ✓ | |
| Ap1310BTKIT1 | | ✓ | ✓ | ✓ | ✓ | ✓ | ✓ | ✓ |



E & OE. ©Copyright 2015 Able Systems Limited. All trade marks acknowledged.
Specifications subject to change without notice. Ap1310/052015/V1

Compact portable printer Ap1310 series
DATASHEET