



## Miniature Indicator Lights

- Nylon body with flush transparent polycarbonate lens
- 6 in. wire leads
- 5/16 in. mounting diameter
- Lamp voltage is AC/DC

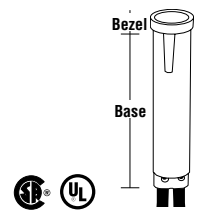





Product	Description	Lens Color	Lamp Voltage	Watts	Amp Rating	Average Life (hrs.)	Lamp Type	Termination Style	Height (Base" x Bezel")	Cat. No.
	Miniature Indicator Light	Red	125V	1/3	2mA Max.	25,000	Neon	6 in. Wire Leads	1.43 x .13	777131
		Green	125V	1/3	2mA Max.	15,000	Neon	6 in. Wire Leads	1.43 x .13	777231
		Amber	125V	1/3	2mA Max.	25,000	Neon	6 in. Wire Leads	1.43 x .13	777331 777331BK†

†Bulk Package of 100

## Alligator Clips

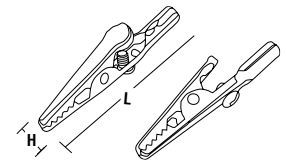
- Great for temporary connections, testing wires and troubleshooting projects
- Spring-loaded, grab-tight jaws make these clips quick and easy-to-use
- For screw and/or crimp connections




Product	Description	Amps	Dimensions (L" x H")	Jaw Opening	Wire Gauge	Qty.	Cat. No.
	Non-Insulated	10	2 x 7/16	5/16 in.	#22 - #14	2	770200L
	Insulated Barrel	10	2-1/2 x 7/16	5/16 in.	#22 - #14	1 Red/1 Black	770204L
	Fully Insulated	10	2-1/2 x 7/16	5/16 in.	#22 - #14	1 Red/1 Black	770205L

## Plier-Type Battery Clamps

- Great for battery charging and test equipment
- Insulated grips are color-coded for positive (red) and negative (black) identification
- For crimp or solder connections

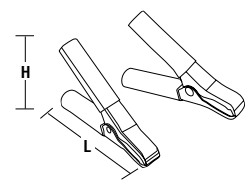

Product	Description	Amps	Dimensions (L" x H")	Jaw Opening	Wire Dia.	Qty.	Cat. No.
	Plier-Type Battery Clip, Steel	50	2-7/8 x 2	1-1/8 in.	9/32 in.	1 Red/1 Black	770213L
	Plier-Type Battery Clip, Copper	75	2-7/8 x 2	1-1/8 in.	9/32 in.	1 Red/1 Black	770212L