

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0022035025](#)
Status: **Active**
Overview: [Mini-SPOX Wire-to-Board Connector System](#)
Description: 2.50mm Pitch, Mini-SPOX PCB Header, Single Row, Vertical, Through Hole, Tin Plating, 2 Circuits, Bag, 3.50mm PC Tail Length

Documents:

| | |
|--------------------------------------|--|
| 3D Model (PDF) | Product Specification 52641001-PS-000 (PDF) |
| Drawing (PDF) | Product Specification PS-5264-001-001 (PDF) |
| 3D Model | Packaging Specification SPK-5267-001-001 (PDF) |
| 2D Drawing (DXF) | RoHS Certificate of Compliance (PDF) |
| 2D Drawing DXF (PDF) | |

Agency Certification


| | |
|-----|---------|
| CSA | LR19980 |
| UL | E29179 |

General

| | |
|----------------|--|
| Product Family | PCB Headers |
| Series | 5267 |
| Application | Signal, Wire-to-Board |
| Component Type | PCB Header |
| Overview | Mini-SPOX Wire-to-Board Connector System |
| Product Name | Mini-SPOX |
| Taxonomy | PCB Headers and Receptacles |
| UPC | 800753591493 |

Physical

| | |
|--------------------------------|------------|
| Breakaway | No |
| Circuits (Loaded) | 2 |
| Circuits (maximum) | 2 |
| Color - Resin | Natural |
| Durability (mating cycles max) | 30 |
| First Mate / Last Break | No |
| Flammability | 94V-0 |
| Glow-Wire Capable | No |
| Guide to Mating Part | No |
| Keying to Mating Part | None |
| Lock to Mating Part | Yes |
| Material - Plating Mating | Tin |
| Material - Plating Termination | Tin |
| Material - Resin | Nylon |
| Net Weight | 223.020/mg |
| Number of Rows | 1 |
| Orientation | Vertical |
| PC Tail Length | 3.50mm |
| PCB Locator | No |
| PCB Retention | Yes |
| PCB Thickness - Recommended | 1.60mm |
| Packaging Type | Bag |
| Pitch - Mating Interface | 2.50mm |
| Plating min - Mating | 4.064µm |
| Plating min - Termination | 4.064µm |
| Polarized to Mating Part | Yes |
| Polarized to PCB | No |
| Shrouded | Fully |
| Stackable | No |

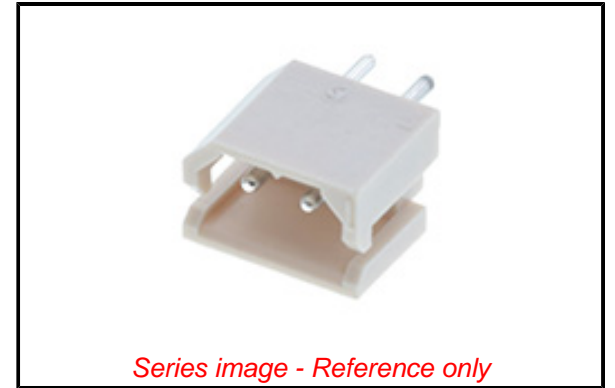

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained per -
D(2022)4187-DC (10
June 2022)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[5267 Series](#)

Mates With

Mini-SPOX Receptacle Housing [5264](#)

| | |
|--------------------------------|----------------|
| Surface Mount Compatible (SMC) | No |
| Temperature Range - Operating | -55° to +105°C |
| Termination Interface: Style | Through Hole |

Electrical

| | |
|-------------------------------|------|
| Current - Maximum per Contact | 3.0A |
| Voltage - Maximum | 250V |

Material Info

| | |
|--------------------|----------|
| Engineering Number | 5267-02A |
|--------------------|----------|

Reference - Drawing Numbers

| | |
|-------------------------|----------------------------------|
| Packaging Specification | SPK-5267-001-001 |
| Product Specification | 52641001-PS-000, PS-5264-001-001 |
| Sales Drawing | 52670001-SD-000 |

This document was generated on 03/08/2023

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION