

M8

0810 ... 0...

Actuator/Sensor Cordsets M8



Actuator/sensor cordset with overmolded connector

Cable end 1:

M8 male, straight, A-coded, IP67

Cable end 2:

blunt cut

Cable:


PVC, black

Approvals:




M8

0810 ... 0...

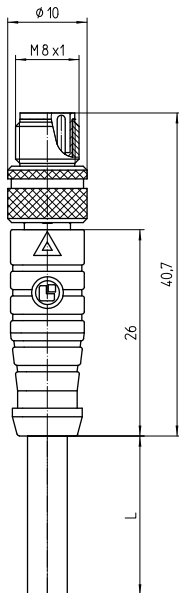

Pin assignments for male M8 connectors, A-coded, front view

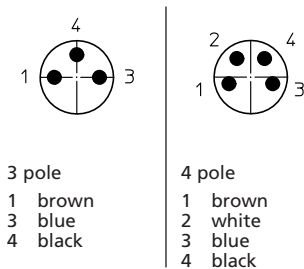

Environmental conditions

Temperature range -25 °C/+80 °C

Materials

Insulating body	TPU GF, HB according to UL94
Contact pin	CuZn, pre-nickel and gold-plated
Overmolding/handle	PVC, HB according to UL94
Knurled screw	CuZn, nickel-plated

Mechanical data

Mating cycles	≥ 100
Insertion force	≤ 23 N ¹
Withdrawal force	≤ 23 N ¹
Protection class	IP67 ²

¹ measured with a proper counterpart

² according to IEC DIN EN 60529, only in locked condition with an appropriate counterpart

Connected cable

Construction PVC, black

Electrical data (at T_{amb} 20 °C)

Contact resistance	≤ 10 mΩ
Rated current	4 A (T _{amb} 40 °C)
Rated voltage	50 V AC/60 V DC (with pollution degree 3)
Rated impulse voltage	1,5 kV
Material group	I (IEC)/0 (UL) (CTI = 600)
Insulation resistance	> 100 MΩ

Associated products

Counterparts

☞ 0800 ... 0...	☞ 0800 ... 3...	☞ 0800F1 ... 0...
☞ 0800F1 ... 3...	☞ 0805 ... 0...	☞ 0805 ... 3...
☞ 0805F1 ... 0...	☞ 0806 ... L1 0...	☞ 0806 ... L1 3...
☞ 0820 ... T8CW ...	☞ 0821 ... T10CP	☞ 0822 ... S9 T8CP
☞ 1210 0800 ... 3...	☞ 1210 0806 ... L1 3...	☞ 5000 04L1 3...
☞ 5000 08L1 3...	☞ 5000 10L1 3...	☞ 5000 12L1 3...
☞ 5012 04L1	☞ 5012 08L1	☞ 5012 10L1

Accessories

☞ 9908 CPM0

M8

0810 ... 0...

M8

0810 ... 0...

Designation	Pole Number	Connected Cable	PU (Pieces)	MDQ (Pieces)	Dimensions L (mm)
0810 03 001 2m	3	PVC, black, 3 x 0.34 mm ² (AWG 22), 910001, UL-style 2464	5	10	2000
0810 03 001 5m	3	PVC, black, 3 x 0.34 mm ² (AWG 22), 910001, UL-style 2464	1	10	5000
0810 04 002 2m	4	PVC, black, 4 x 0.34 mm ² (AWG 22), 910002, UL-style 2464	5	10	2000
0810 04 002 5m	4	PVC, black, 4 x 0.34 mm ² (AWG 22), 910002, UL-style 2464	1	10	5000

Packaging:
in a plastic bag