



## VarioPlate Small Blindinsert

Art.-No. 440-00004 | VP-S\_0\_Blindinsert-PL-BK | [Details](#)

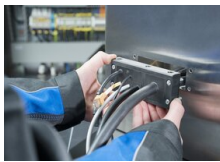

- Integrated cable diameter tolerance compensation
- Modular application for both insert sizes (S and L)
- Integrated strain relief
- IP 65 and IP 66

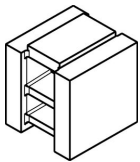


More products in this product group:

[VarioPlate Cable Entry System >](#)

Base Data

|                           |                                                                                                                                                                                                                                                                                                                                         |
|---------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Application               | VarioPlate cable entry system inserts grommets are used in combination with VarioPlate frames for time and space saving cable installation on all types of panel builder housings and controll boxes. The versatile design covers cable diameter from 3 to 33mm. Inserts grommets are available in one, two, four holes and blindplugs. |
| Application Tool          | <a href="#">VP Mounting Tool</a>                                                                                                                                                                                                                                                                                                        |
| Colour                    | Black (BK)                                                                                                                                                                                                                                                                                                                              |
| Description               | VarioPlate Small Blindinsert                                                                                                                                                                                                                                                                                                            |
| Material                  | Plastic (PL)                                                                                                                                                                                                                                                                                                                            |
| Pack Content              | 20 pcs.                                                                                                                                                                                                                                                                                                                                 |
| Package Content packed in | bag                                                                                                                                                                                                                                                                                                                                     |
| PART DESCRIPTION          | VP-S_0_Blindinsert-PL-BK                                                                                                                                                                                                                                                                                                                |
| Product Family            | VarioPlate Small Blindinsert                                                                                                                                                                                                                                                                                                            |
| Product Group             | VarioPlate Cable Entry System                                                                                                                                                                                                                                                                                                           |
| Variant                   | Both sides open                                                                                                                                                                                                                                                                                                                         |

# Product Dimensions

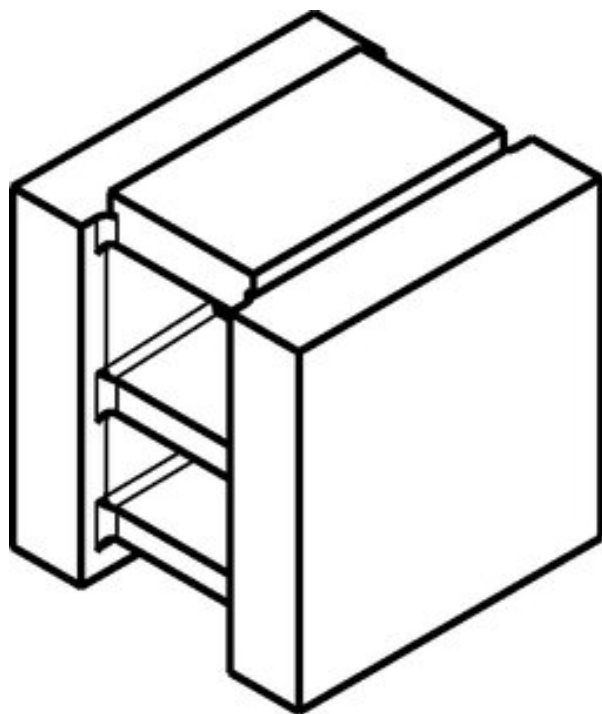

|            |          |
|------------|----------|
| Depth (D)  | 32.00 mm |
| Height (H) | 21.8 mm  |
| Length (L) | 21.1 mm  |
| Width (W)  | 21.1 mm  |

## Specifications

|                               |                                                                                                                                                                                                                                                              |
|-------------------------------|--------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| ELV compliant (Article 4 - 2) | YES                                                                                                                                                                                                                                                          |
| Flammability                  | UL 94 V0                                                                                                                                                                                                                                                     |
| Halogen-free                  | Yes                                                                                                                                                                                                                                                          |
| Hazardous good                | No                                                                                                                                                                                                                                                           |
| IP-Rating                     | IP66                                                                                                                                                                                                                                                         |
| Operating Temperature         | -40 °C to +100 °C                                                                                                                                                                                                                                            |
| Self extinguishing (Yes/No)   | Yes                                                                                                                                                                                                                                                          |
| Specifications                |    |
| Specifications                | csa-C22.2 No. 94.1, csa-C22.2 No. 94.2, UL 50, UL 50E                                                                                                                                                                                                        |
| UL OCD link                   | <a href="#">Link</a> <a href="#">Link</a>                                                                                                                                                                                                                    |
| UL-File Number                | E526974                                                                                                                                                                                                                                                      |

# Logistics and Packaging

|                           |               |
|---------------------------|---------------|
| GTIN-13 / EAN             | 4031026686615 |
| Packaging 1 - Height (m)  | 0.072 m       |
| Packaging 1 - Length (m)  | 0.11 m        |
| Packaging 1 - Qty         | 20            |
| Packaging 1 - Type        | carton        |
| Packaging 1 - Volume (m³) | 0.00083 m³    |
| Packaging 1 - Weight (kg) | 0.161 kg      |
| Packaging 1 - Width (m)   | 0.105 m       |
| Packaging 2 - Height (m)  | 0.216 m       |
| Packaging 2 - Length (m)  | 0.3048 m      |
| Packaging 2 - Type        | carton        |
| Packaging 2 - Volume (m³) | 0.0176 m³     |
| Packaging 2 - Width (m)   | 0.267 m       |

## More Information

Subscribe to our newsletter >

