


Pluggable Terminal Block Header

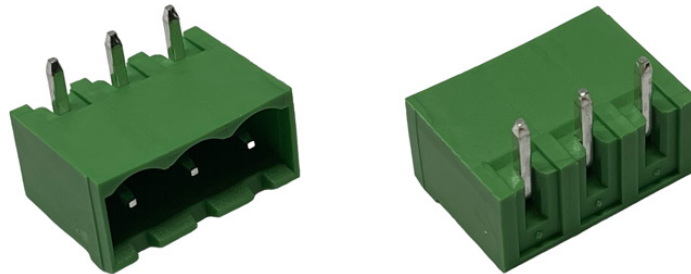

3 Ways shown, various available

Orientation	Through Hole Right Angle
Current Rating	15 A
Voltage Rating	300 V
Dielectric Voltage Withstand	1600 V
Pitch Spacing	5.08 mm
Housing	PA66, UL94V-0
Mounting Type	Wave Soldering
Pin Layout	Linear
Temperature Range	-40°C ~ +105°C
Conductor Material	Copper Alloy, Tin Plated
Our Compatible Plug Connectors	TC 47 508P Series

See Product Page for Diagram & Dimensions :

www.thermodatacomponents.co.uk/PluggableTerminalBlockHeaderRightAngle