


Cordless Pyropen Set with gas bottle

Product no.: T0051606099

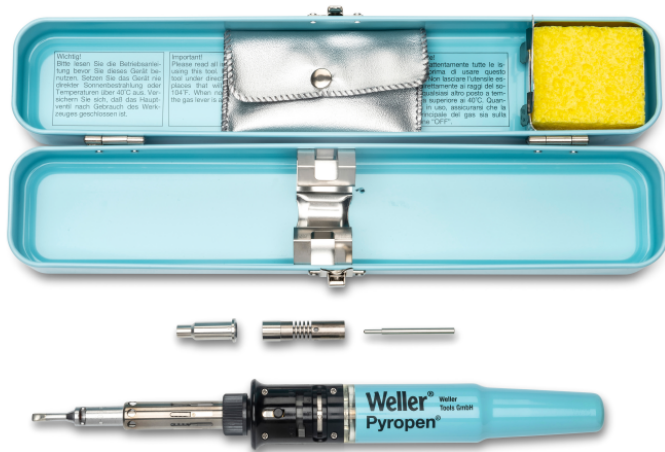

Benefits



- › Manual-ignition - can be easily ignited manually with lighter or match
- › Ready to use within seconds - Rapid heat up time, no long waiting for heating up the iron
- › Solder on the go, even outdoors - Complete your soldering task anywhere, without the need for a mains supply or an obstructing cable in the way
- › Solder on the go, even outdoors - Complete your soldering task anywhere, without the need for a mains supply or an obstructing cable in the way
- › High versatility with included accessories - additional hot blow and arc torch function for shrinking hoses and brazing
- › Temperature adjustable from 200° to 1300°C - adjustable temperatures between 200° to 500°C when used as soldering iron, 650°C when used as hot air blower, 1300°C when used as blow torch
- › Easy refill with Weller butane gas - Does not require cords, batteries or cartridges - Refills with butane fuel - Weller® Cat. no. WB1 or WB2



Technical Data

Active Tip heating element technology	---
Power Response heating element technology	---
Silver Line heating element technology	---
Voltage	---
Power	ca. 20 - 80 W
Tip range	70-xx
Supply unit	---
WX-compatible	---
Temperature range °C	200 - 500
Temperature range °F	400 - 930
Heating time	---
Safety rest	---
Safety rest (optional)	---
Barrel	---
Integrated direct extraction	---