


LTS Galvanised Steel Conduit with PVC Cover 10m

Art.-No. 166-31912 | LTS20-GS/PVC-BK | [Details](#)



- Liquid-tight (IP68 and IP69k with LTS fittings)
- High compression, tensile and impact strength
- Good flexibility
- Smooth outer cover does not wrinkle when bent
- Good resistance to acids, petrol, oils and greases
- Suitable for outdoor use

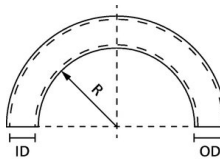


More products in this product group:
[Metallic conduits with liquid-tight cover >](#)

Base Data

Application	Flexible galvanised steel conduit with smooth, liquid-tight PVC cover. Fulfills IP66, IP67, IP68 and IP69k with LTS-fittings. LTS is used in machine tools and outdoor installations, wherever liquid-tight is a requirement.
Application Tool	CONCLAMP
Colour	Black (BK)
Conduit Model	Metallic with smooth plastic coating, liquid-tight
Material	Galvanised Steel (GS), Polyvinylchloride (PVC)
Pack Content	10 m
Package Content packed in	reel
PART DESCRIPTION	LTS20-GS/PVC-BK
Product Family	LTS Galvanised steel conduit, PVC cover
Product Group	Metallic conduits with liquid-tight cover

Product Dimensions

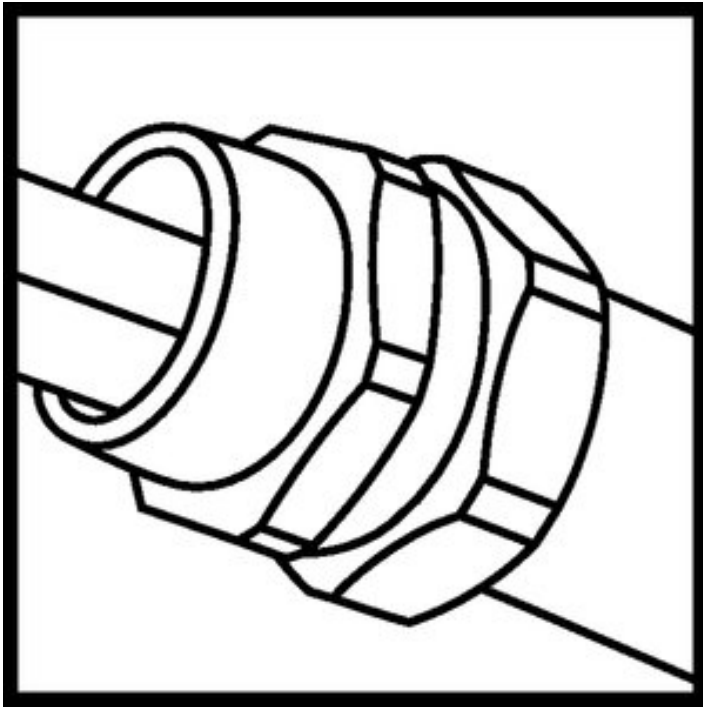

Bending Radius min. (R)	65 mm
Diameter (D)	16.0 mm
Inside Ø (ID)	16.0 mm
Nominal Ø	20 mm
Nominal Ø	0.81 "
Outside Ø (OD)	21.1 mm
Weight	407 g/m

Specifications

CE Certification	Yes
Electrical characteristics	Not specified
ELV compliant (Article 4 - 2)	YES
EN61386 Classification	443340684410
Hazardous good	No
IP-Rating	IP69k, IP68
Operating Temperature	-20 °C to +105 °C
Specifications	RoHS ✓

Logistics and Packaging

GTIN-13 / EAN	4031026319919
Packaging 1 - Height (m)	0.108 m
Packaging 1 - Length (m)	0.403 m
Packaging 1 - Qty	10
Packaging 1 - Type	reel
Packaging 1 - Volume (m ³)	0.01754 m ³
Packaging 1 - Weight (kg)	4.69 kg
Packaging 1 - Width (m)	0.403 m
Packaging 4 - Length (m)	1.2 m
Packaging 4 - Qty	420
Packaging 4 - Type	pallet
Packaging 4 - Weight (kg)	217.98 kg
Packaging 4 - Width (m)	0.8 m
Reel Length	10 m

More Information

Subscribe to our newsletter > 