

NEBO[®]

BIG LARRY[™]

LIGHT MODES

- Flashlight (220 lumens): 8 hours / 82 meters
- Work Light (600 lumens): 2.5 hours / 33 meters
- Red (40 lumens): 20 hours / 7 meters
- Red Strobe (40 lumens): 40 hours / 7 meters

DESIGN

- Dimming + Power Memory Recall
- Direct-to-Red
- Anodized aircraft-grade aluminum
- Water and impact-resistant (IPX4)
- Steel pocket clip with hanging hole
- Powerful magnetic base

OPERATION


- Front-positioned button

BATTERIES

- Powered by 3 AA batteries (included)

SPECS

- 0.42 lb.
- (H) 7.85" x (W) 0.965" x (D) 1.18"

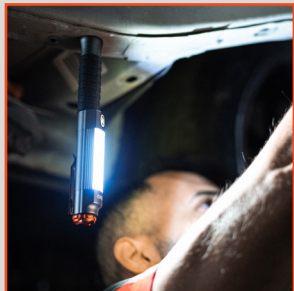

CALIFORNIA REQUIRED ⚠️ WARNING | Cancer and Reproductive Harm | www.P65Warnings.ca.gov



BIG LARRY IS BACK AND BRIGHTER THAN EVER

The new and improved BIG Larry outputs **600 lumens** with the C-O-B work light and **220 lumens** from the top light. The **red C-O-B light** is perfect for distress signaling or roadside emergencies. The **steel clip** and **magnetic base** provide convenient hands-free lighting options.

UPC CODE

ITEM

645397939658 NEB-FLT-1041



PDQ Dimensions

(H) 1.4" x (W) 5.7" x (D) 10.78"

Natralock Dimensions

(H) 11.8" x (W) 4.88" x (D) 1"