



• MT-510

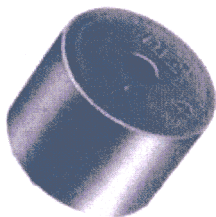


FEATURES:

- Low consumption
- Flange mounting with wire leads

DIMENSIONS: (Unit: mm)

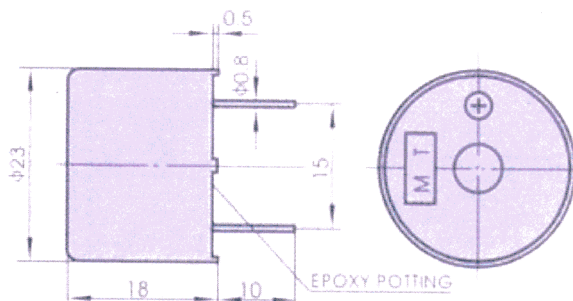

CHARACTERISTICS:

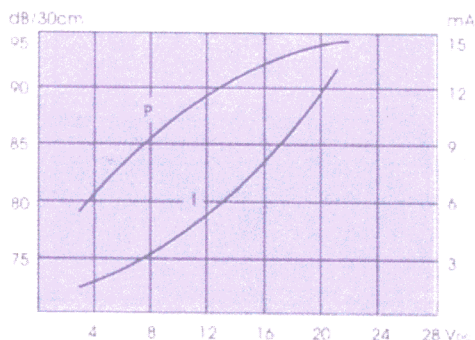

ELECTRICAL SPECIFICATIONS :

Model No.	MT-510
Min. Sound Pressure Level (dB)	85 /12V _{DC} /30cm
Rated Voltage (V _{DC})	12
Operating Voltage (V _{DC})	3 ~ 20
Max. Consumption (mA)	12 /12V _{DC}
Oscillating Frequency (kHz)	3.15 ± 0.5
Tone Nature	Continuous
Operating Temperature (°C)	-20 ~ +70
Weight (g)	7
Case Material/Colour	PA6/Black

PACKING INFORMATION :

Packing :	1600 pcs per export carton
Carton Size :	47 X 30.5 X 25 cm
G. Weight :	13.3 kgs
N. Weight :	11.5 kgs