


Low Profile Category 6 6C Outlet:

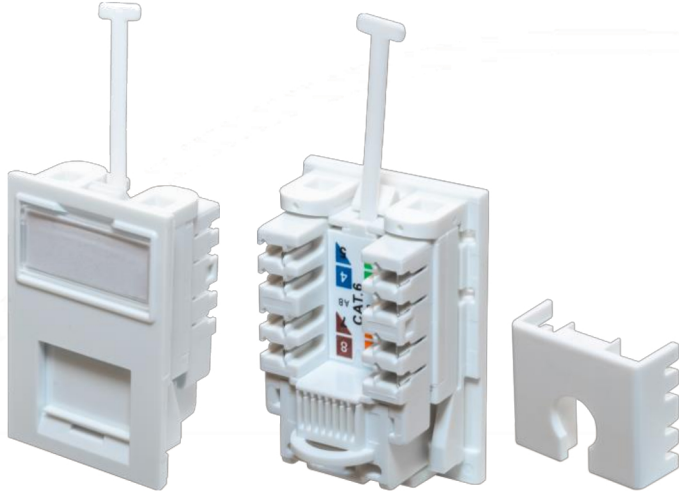

Low Profile Category 6 6C Outlet (SJ6whje, SJ6whje#24):

This affordable outlet which easily performs to Category 6 TIA/EIA-568-C.2-1 at permanent link, can be quickly and easily terminated and fits most standard 6C faceplates

Features:

- Performs to Category 6 at permanent link level with good headroom
- Low profile design, shuttered front aperture protects against dust
- Fitted with industry standard Krone (LSA+) type IDC connections
- Compatible with most '6C' style faceplates
- 'Slip-in' label facility for port identification
- Integral cable tie point. Cable retention clip also supplied along with additional flexible cable tie facility
- Available in individual polythene bags or in 'bulk packs' of 24 without individual poly bags

Specifications:

- Weight:
SJ6whje: 18g SJ6whje#24: 356g
- Dimensions (as packed):
SJ6whje: 40 x 60 x 20mm SJ6whje#24: 240 x 225 x 30mm
- Colour: White (RAL 9003)

- **Materials:**
 - IDC:
 - IDC cap: ABS, UL 94-HB IDC
 - Housing: PC + Glass fibre UL 94V-2 IDC
 - Terminal: Tin plated phosphor bronze
 - RJ45 Jack:
 - Housing: ABS UL 94-HB
 - Contact bracket: PC 1250Y, UL 94V-0
 - RJ45 Jack Contact
 - Material: Nickel plated phosphor bronze
 - Finish: 50µ"/1.27 µm gold plating on plug contact area
- T568A and T568B wiring sticker
- Insertion force: 20N max.
- Retention strength: 7.7kg between jack and plug
- Operating temperature: -10°C to 60°C
- Suitable for 22-26 AWG stranded and solid wire with Krone (LSA+) type punch down tool

Packaging:

SJ6jewh: individually bagged, then bagged in 20s then in 100s
SJ6jewh#24: in box of 24 pcs, then in outer carton of 24 boxes

Commodity code: 84733020

EAN: SJ6whje: 5055386510617

SJ6whje#24: 5055386510624

Country of Origin: China