

# Panasonic

# Mini series

EY 4610



Cordless Mini Grinder

EY 4610

Cordless Mini LED Flashlight

EY 3710

Cordless Screw Driver

EY7412

USB Charging

EY 3710

IP56

EY 7412

## EY 4610

Cordless Mini Grinder



### Bit set

- Diamond bit (engraving)
- Multi-purpose bit (engraving/grinding)
- Drill bit
- Sanding bit
- Polishing felt bit



Mini Grinder bit set  
EY 9X022 E



## EY 3710

Cordless Mini LED Flashlight



2WAY



Spotlight : 2000 lx




Wide Angle Light : 350 lx



IP56

<Back side>  
Built-in hook  
Magnet

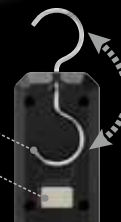


Run-down driving

Finish tightening



Powered

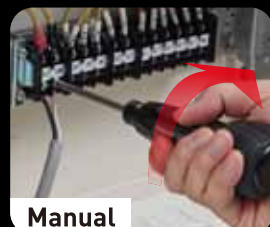

Manual

Convenient single-handed operation in any direction

## EY7412

Cordless Screw Driver




Torque Adaptor  
EY 9BP505 E



# Meets the demands of your job with compact body



Rigid housing means high durability

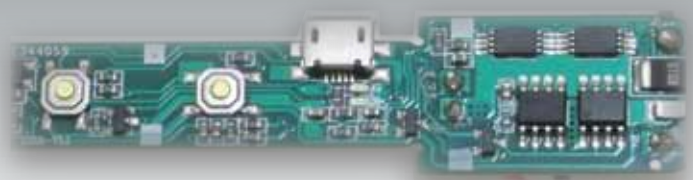

Integrated overcharge / discharge protection circuit for longer life

## Cordless Mini Grinder EY 4610



Specifications (approx.)

Chuck	ø0.5~3.2
3-Step rotation speed	Low 10,000rpm / Middle 14,000rpm / High 21,000rpm
Battery (built-in)	Li-ion DC3.7V 850mAh
Charging terminal	Micro USB Type-B DC5V
Charging time	65 minutes with commercially available USB charging adaptor 5V 1A
Dimensions / Weight	153 x 33 mm / 125 g
Battery capacity (no load with full charge)	approx. 55 minutes

## Cordless Mini LED Flashlight EY 3710



Specifications (approx.)

Illuminance	Spot Light 2,000 lx / Wide Angle Light 350 lx
Battery (built-in)	Li-ion DC3.7V 850mAh
Charging terminal	Micro USB Type-B DC5V
Charging time	65 minutes with commercially available USB charging adaptor 5V 1A
Dimensions / Weight	145 x 50 x 33 mm / 160 g
Battery capacity (with full charge)	Spot Light approx. 3 hours / Wide Angle Light approx. 2 hours
Dust / Water protection	IP56

## Cordless Screw Driver EY7412



### Bit set included

Single-headed,  
13mm shank length

\*#2⊕150mm \*#2⊕100mm \*#2⊕45mm

\*Width 6mm ⊖100mm \*#1⊕100mm

Specifications (approx.)

Chuck	1/4"(6.35mm) Hex one-touch bit lock	
Maximum instant torque	1.0 Nm	
Shaft lock durability	up to 8 Nm	
Speed at no load	230 min <sup>-1</sup>	
Battery (built-in)	Li-ion DC3.7V 850mAh	
Charging terminal	Micro USB Type-B DC5V	
Charging time	25 minutes with commercially available USB charging adaptor 5V 2A 35 minutes with commercially available USB charging adaptor 5V 1A 45 minutes with Panasonic EY37C4/LED light, EY37C5/Speaker	
Dimensions / Weight	L 128 x H 45 x W 42 mm / 165 g	
Battery capacity (approx. with full charge)	Small metal screws	M3 x 5 without washer 620 M6 x 10 without washer 540
	*Ensure the finish fastening torque by manual tightening.	

# Panasonic®

 
### Panasonic Power Tools

Panasonic UK  
Maxis 2, Western Road,  
Bracknell, Berkshire  
RG12 1RT  
United Kingdom

Produced in Japan 01/2022

© 2022 Panasonic Electric Works Europe AG

[www.panasonic-powertools.eu](http://www.panasonic-powertools.eu)



### Panasonic Electric Works Europe AG

The design and specification of products are constantly changing in the interest of improvement. Whilst every care has been taken in preparation of this catalogue, some changes may not have been indicated and may have occurred after publication. Please check with your Panasonic dealer for details. Panasonic Electric Works Europe AG cannot accept responsibility for any errors and omissions.