

# PSI Displays Ltd



Suite C2, Butts Business Centre, Butts Road, Chiseldon, Swindon, Wiltshire, SN4 0PP. UK.

Tel: +44 (0) 1793 740456

 

e-mail: sales@psidisplays.co.uk Website www.psidisplays.co.uk

## LCD COLOUR MONITOR Model No. L156HM

15.6" TFT LCD Full HD Colour Wide Screen Monitor 1920 x 1080P with LED Back Light, inputs of HDMI x 2, DVI, VGA, Composite video In/Out BNC, Y/C (S-Video) in. Audio In/Out and via Speakers, I/R Remote Control. **Options:** 19" Rack Mount, Touch screen or Glass front. Other sizes available.



19" Rack Mount option

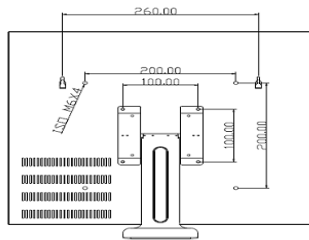

### Main Features:

- Resolution: 1920 x 1080P – Full HD
- Picture Ratio: 16:9
- Brightness: 450 cd/m2. - LED Back light.
- Contrast Ratio: 800:1
- Inputs: HDMI x 2, DVI, VGA, Composite Video, S-Video (Y/C), Audio.
- Outputs: Composite Video BNC, Audio.
- Mounting: VESA 75 or 100, Key Hole, Stand.
- Slim Aluminium cabinet in Black.
- 3D De-Interlaced Technology.
- Anti-blur/image auto.
- Speaker: 2 Watts max.
- USB Socket: Media and Service use.

The L156HM with LED back light and TFT technology offers Professional sharp images and with high contrast ratio 800:1 and Brightness 450 cd/m2 gives superb pictures. With HDMI, DVI, VGA, S-Video (Y/C) Composite Video In/Out BNC Connectors, Video Loop through, Audio In/Out and Audio via speakers making it a truly versatile Monitor. Mounting options offering VESA 75 + 100 & Key hole mounting and with a Desk lean-to stand. Infra-Red remote control. and all finished in a Smart tough Aluminium Metal housing. This compact unit is ideal for Multimedia Video and Surveillance systems applications.

### SPECIFICATIONS:

- Active area: 344.16 x 193.59 (WxH)mm. • 16.2M Colours. • PAL and NTSC Auto.
- Response Time: 13/12 ms (Tr/Tf ). • Viewing angle: Left/Right: 85°, Up/ Down 85°.
- Controls/Indicators: Front: On LED, I/R sensor. Rear: Source, Menu, Item, Up, Down, Power.
- Power Source: 12V DC, 1.1 Amp, 13 Watts approx. AC Adaptor: 90-264 Vac 50/60Hz 1.5Amps.
- Dimensions: 383 x 231 x 47 (62 with stand). Carton: 445 x 390 x 145 (WxHxD)mm.
- Weight: Unit: 3.4 Kgms, Carton: 4.37 Kgms. • Temp: Operation: 0°C~50°C.

**Connections:** HDMI In x 2: Type A sockets. DVI: DVI-D socket. VGA: 15 pin Sub-D socket. Composite Video In/Out: BNC sockets. Y/C (S-Video) Input: 4 pin mini din socket. Audio In/Out: 3.5mm Jack sockets. DC input: 2.1mm socket. AC adaptor: IEC socket. USB In: Type A socket for Media and service use only.

**Standard accessories:** AC adapter, UK AC Mains Lead, I/R Remote Control.

- All information correct at time of going to press. Design and specification are subject to change without prior notice. E&EO