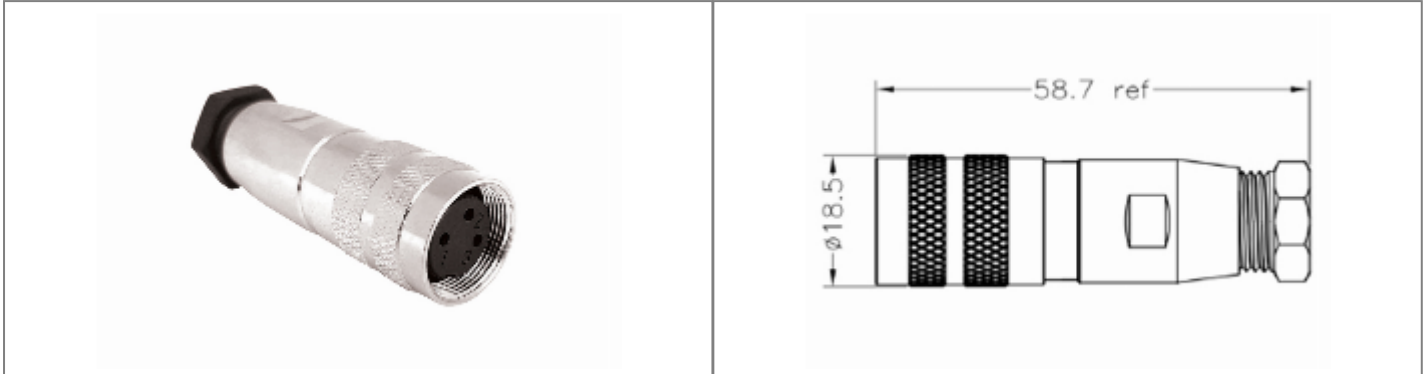


# PXMBNI16FBF08ASCPG9 Datasheet

## Product Name // M16 Series A Code Brass Nickel Plated PG9 Flex Body 8 Contact Socket

[View Product Page](#)


### // Product Description:

- ⬡ M16 Series Brass Nickel Plated Flex Body Connectors
- ⬡ Water and dustproof to IP67 when mated with compatible connector
- ⬡ A Code
- ⬡ Socket only
- ⬡ 3, 4, 5, 6, 8, 12 Contact
- ⬡ Solder Terminals
- ⬡ Mate with M16 Series Inline Body and Panel Mount Connectors

### // General Information:

Product Display Title:	M16 Series Brass Nickel Plated Flex Body Connectors
Product Family:	Circular Automation Connectors
Product Series:	M16 Series
Change Notes:	PRODUCT-MOQ-ADJUSTMENT
Body Material:	Brass - Nickel Plated
Contact Type:	Socket Contact
Coupling Type:	Screw
Current Max:	5A
Diameter Over Coupling Ring Mm:	18.5mm
Function:	Flex Cable Connector Body
Ip Rating:	IP67
M12 Series Mounting Nut:	PG9
Max Operating Temperature:	+80°C
Min Operating Temperature:	-25°C
Number Of Contacts:	8 Contacts
Pin Layout Code:	A Code
Thread Size:	M16 x 0.75
Voltage Max:	60V

### // Product PDF Links

[M16 Series automation connectors...](#)


Have a question or project enquiry  
you'd like to talk to us about?

[Click Here To Contact Us](#)