

Series 09, Universal Switch

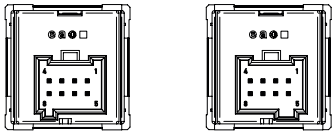
Contact

Customer Name		Name of EAO Sales Person	
Delivery Address		Phone number	
		Signature	
		Date	



One order form per universal switch configuration.

Features		Product options	Variants		
			STANDARD	DUAL CONTACT	
				NO-NO	NO/NC-NO
Electrical properties		12 V			
		24 V			
		12 V Namur $R_s=120\ \Omega / R_p = 1\ K\Omega$			
		24 V Namur $R_s=120\ \Omega / R_p = 1\ K\Omega$			
Haptics		Firm haptics (short travel)			
		Soft haptics (long travel)			
		Without haptics			
Symbol illumination	   White Red Without	White			
		Red			
		Without symbol illumination			
Status indicator	   Without One LED Three LEDs	Without status indicator			
		One red status indicator			
		Three red status indicators			

Features		Product options	Variants		
			STANDARD	DUAL CONTACT	
				NO-NO	NO/ NC-NO
TYCO Connector		Tyco 8P-1745000-3 (black)			
		Tyco 8P-1745000-4 (grey)			
		Without connector			
Symbol	ISO 7000  Customized	ISO 7000- XXXX*			
		Customized symbol**			
Symbol direction	 0°  90°  180°  270°	0°			
		90°			
		180°			
		270°			

Notes



For this variant the option is not available

* Please indicate the four digits of the ISO 7000 number

** For customized symbols, please send us the corresponding file