

Cat6 Patch Cables

Slim Cat6 U/UTP LSZH Patch Cables

Part No: 2994 - (Length) + (Colour) see chart

[View Online](#)



Available in 10 Colours with 10 different length options the Videk range of Slim Cat6 cables are designed to support high performance & high density networks. Manufactured to Cat6 standards using 28AWG LSZH cable and high quality plugs featuring a snag free boot these cables measure nearly half the diameter of traditional Cat6 cable allowing for a clutter free networking environment.

Features & Benefits

- Slim Cat6 cables helps create a clutter free networking environment
- Designed for High Performance & High Density Networks
- Support POE/POE+ applications
- Featuring LSZH stranded UTP cable along with 50 micron gold RJ45 connectors
- Fully backward compatible with Cat.5/Cat.5E networks

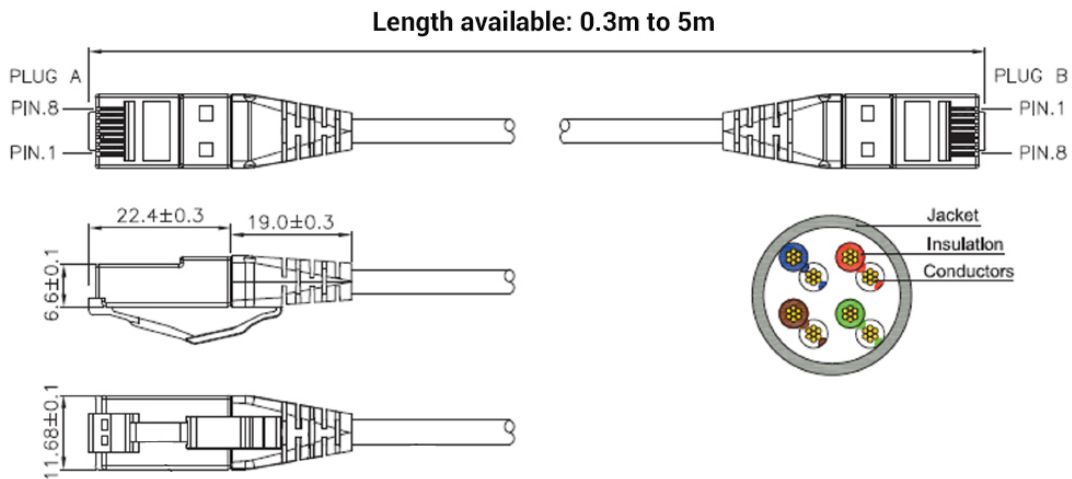


VIDEK

Cat6 Patch Cables

Slim Cat6 U/UTP LSZH Patch Cables

Part No: 2994 - (Length) + (Colour) see chart

[View Online](#)


Part Number Chart

Length	Blue	Black	Grey	Purple	Red
0.15 Metre	2994-0.15B	2994-0.15BK	2994-0.15GY	2994-0.15PR	2994-0.15R
0.2 Metre	2994-0.2B	2994-0.2BK	2994-0.2GY	2994-0.2PR	2994-0.2R
0.3 Metre	2994-0.3B	2994-0.3BK	2994-0.3GY	2994-0.3PR	2994-0.3R
0.5 Metre	2994-0.5B	2994-0.5BK	2994-0.5GY	2994-0.5PR	2994-0.5R
0.75 Metre	2994-0.75B	2994-0.75BK	2994-0.75GY	2994-0.75PR	2994-0.75R
1 Metre	2994-1B	2994-1BK	2994-1GY	2994-1PR	2994-1R
1.5 Metre	2994-1.5B	2994-1.5BK	2994-1.5GY	2994-1.5PR	2994-1.5R
2 Metre	2994-2B	2994-2BK	2994-2GY	2994-2PR	2994-2R
3 Metre	2994-3B	2994-3BK	2994-3GY	2994-3PR	2994-3R
5 Metre	2994-5B	2994-5BK	2994-5GY	2994-5PR	2994-5R

Cat6 Patch Cables





Slim Cat6 U/UTP LSZH Patch Cables

Part No: 2994 - (Length) + (Colour) see chart

[View Online](#)



Part Number Chart

Length	Green 	Pink 	Orange 	White 	Yellow 
0.15 Metre	2994-0.15G	2994-0.15PK	2994-0.15RG	2994-0.15W	2994-0.15Y
0.2 Metre	2994-0.2G	2994-0.2PK	2994-0.2RG	2994-0.2W	2994-0.2Y
0.3 Metre	2994-0.3G	2994-0.3PK	2994-0.3RG	2994-0.3W	2994-0.3Y
0.5 Metre	2994-0.5G	2994-0.5PK	2994-0.5RG	2994-0.5W	2994-0.5Y
0.75 Metre	2994-0.75G	2994-0.75PK	2994-0.75RG	2994-0.75W	2994-0.75Y
1 Metre	2994-1G	2994-1PK	2994-1RG	2994-1W	2994-1Y
1.5 Metre	2994-1.5G	2994-1.5PK	2994-1.5RG	2994-1.5W	2994-1.5Y
2 Metre	2994-2G	2994-2PK	2994-2RG	2994-2W	2994-2Y
3 Metre	2994-3G	2994-3PK	2994-3RG	2994-3W	2994-3Y
5 Metre	2994-5G	2994-5PK	2994-5RG	2994-5W	2994-5Y