



MASTER GLASS LED candles and lusters



MAS LEDCandleDT5.9-60W E14 927 B35 CL G

Featuring a classic heritage design, Classic filament LED Lamps combine the familiar shapes of incandescent candles and lusters with the benefits of the long-lasting LED technology. It is an idea product to provide customers with cozy atmosphere. The MASTER LED candles and lusters can be dimmed for different lumen level and also for the different color temperature. MASTER Glass Led Bulbs deliver significant energy savings, offering even 30% more compared to normal LED and provides excellent quality of light. By offering a lifetime of 25,000 hours it reduces maintenance costs.

Product data

General Information	
Lighting Technology	LED
Flux measurement reference	Sphere
Switching Cycle	20,000
Nominal lifetime	25,000 hour(s)
Cap-Base	E14 [E14]
Light Technical	
Color Code	922-927 [CCT of 2200K-2700K]
Luminous Flux	806 lumen
Color Designation	Warm Glow(WG)
Correlated Color Temperature (Nom)	2200 2700 K
Luminous Efficacy (rated) (Nom)	136 lm/W
Color Consistency	<6
Color rendering index (CRI)	90
LLMF At End Of Nominal Lifetime (Nom)	70 %


Operating and Electrical	
Line Frequency	50 to 60 Hz
Input Frequency	50 to 60 Hz
Power Consumption	5.9 W
Lamp Current (Nom)	40 mA
Wattage Equivalent	60 W
Starting Time (Nom)	0.5 s
Warm-up time to 60% light	0.5 s
Power Factor (Fraction)	0.6
Voltage (Nom)	220-240 V
Temperature	
Ambient temperature range	-20 °C to 45 °C
T-Case Maximum (Nom)	70 °C

MASTER GLASS LED candles and lusters

Controls and Dimming	
Dimmable	Only with specific dimmers
Mechanical and Housing	
Bulb Finish	Clear
Bulb Material	Glass
Bulb Shape	B35 [B 35mm]
Approval and Application	
Energy Efficiency Class	D
Energy Consumption kWh/1000 h	6 kWh
EPREL Registration Number	1109147
CE mark	Yes


EU RoHS compliant	Yes
Product Data	
Full product code	871951444957200
Order product name	MAS LEDCandleDT5.9-60W E14 927 B35 CL G
Order code	929003013982
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	10
Material number (12NC)	929003013982
Full product name	MAS LEDCandleDT5.9-60W E14 927 B35 CL G
EAN/UPC - Case	8719514449589

Dimensional drawing

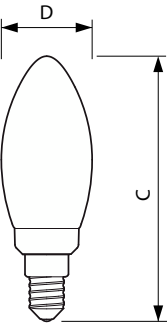


Product	D	C
MAS LEDCandleDT5.9-60W E14 927 B35 CL G	35 mm	97 mm

Photometric data

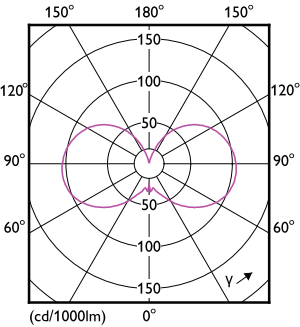


Light Distribution Diagram - MAS LEDCandleDT5.9-60W E14 927 B35 CL G

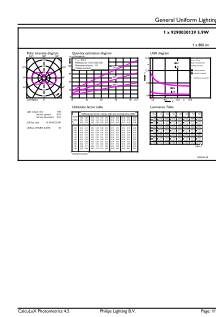

General uniform lighting - MAS LEDCandleDT5.9-60W E14 927 B35 CL G


MASTER GLASS LED candles and lusters

Photometric data

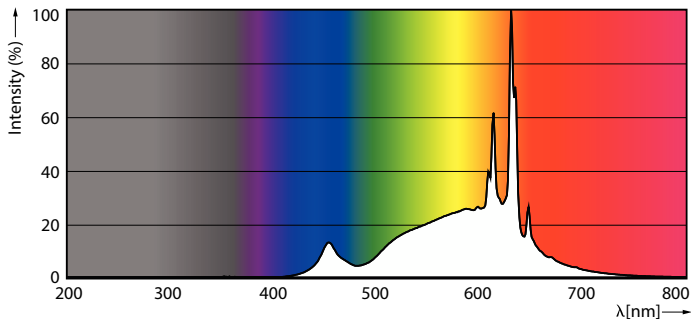


Spectral Power Distribution Colour - MAS LEDCandleDT5.9-60W E14 927 B35 CL G

Lifetime

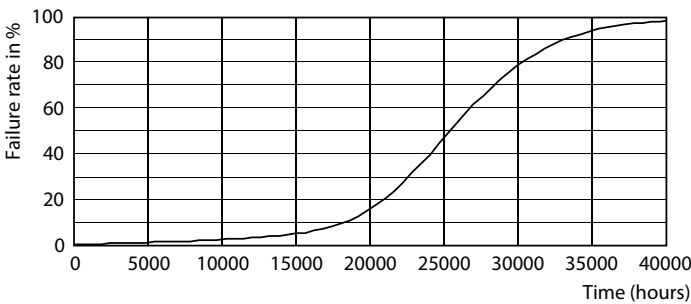

Life Expectancy Diagram - MAS LEDCandleDT5.9-60W E14 927 B35 CL G

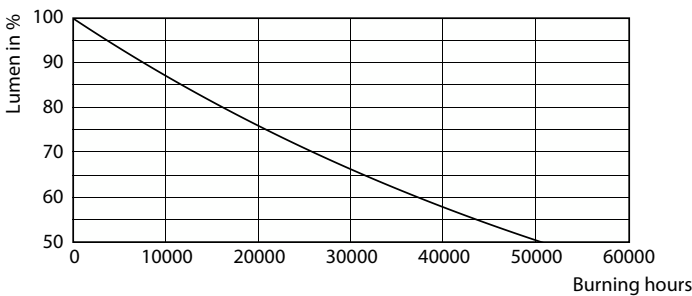

Lumen Maintenance Diagram - MAS LEDCandleDT5.9-60W E14 927 B35 CL G

