



CorePro Plastic LEDbulbs

CorePro LEDbulb ND 4.9-40W A60 B22 930UK

The CorePro LED bulb is the perfect bulb for your basic lighting needs. It provides beautiful light and dependable performance you expect from LED at an affordable price. CorePro LEDbulbs are compatible with existing fixtures with an E27 or B22 holder and are designed for retrofit replacement of incandescent bulbs. They deliver huge energy savings of 80% and provides excellent quality of light. By offering a lifetime of 15,000 hours it reduces maintenance costs.

Product data


General Information		Operating and Electrical	
Lighting Technology	LED	Line Frequency	50 Hz
Flux measurement reference	Sphere	Input Frequency	50 Hz
Switching Cycle	50,000	Power Consumption	4.9 W
Nominal lifetime	15,000 hour(s)	Lamp Current (Nom)	45 mA
Cap-Base	B22 [B22]	Wattage Equivalent	40 W
Light Technical		Starting Time (Nom)	0.5 s
Color Code	930 [CCT of 3000K]	Warm-up time to 60% light	0.5 s
Beam Angle (Nom)	180 degree(s)	Power Factor (Fraction)	0.4
Luminous Flux	470 lumen	Voltage (Nom)	220-240 V
Color Designation	White (WH)	Temperature	
Correlated Color Temperature (Nom)	3000 K	Ambient temperature range	-20 °C to 45 °C
Luminous Efficacy (rated) (Nom)	95 lm/W	T-Case Maximum (Nom)	80 °C
Color Consistency	<6	Controls and Dimming	
Color rendering index (CRI)	90	Dimmable	No
LLMF At End Of Nominal Lifetime (Nom)	70 %		

CorePro Plastic LEDbulbs

Mechanical and Housing	
Bulb Finish	Frosted
Bulb Material	Plastic
Bulb Shape	A60 [A 60mm]
Approval and Application	
Energy Efficiency Class	F
Energy Consumption kWh/1000 h	5 kWh
EPREL Registration Number	1218490
EU RoHS compliant	Yes
Product Data	
Full product code	871951447502100


Order product name	CorePro LEDbulb ND 4.9-40W A60 B22 930UK
Order code	929003543099
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	10
Material number (12NC)	929003543099
Full product name	CorePro LEDbulb ND 4.9-40W A60 B22 930UK
EAN/UPC - Case	8719514475038

Dimensional drawing

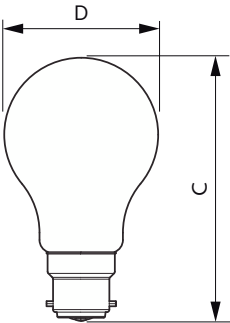


Product	D	C
CorePro LEDbulb ND 4.9-40W A60 B22 930UK	60 mm	105 mm

Photometric data

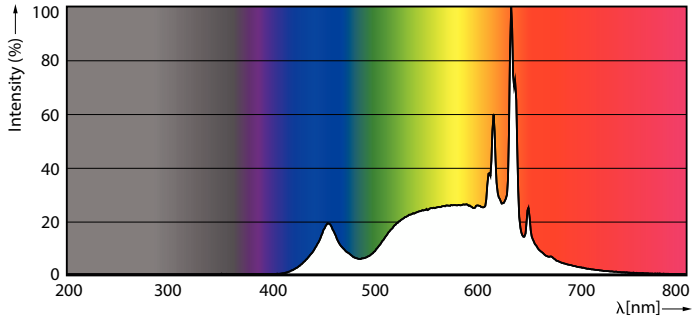


Spectral Power Distribution Colour - CorePro LEDbulb ND 4.9-40W A60 B22 930UK

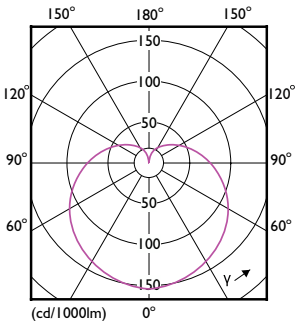

Light Distribution Diagram - CorePro LEDbulb ND 4.9-40W A60 B22 930UK

CorePro Plastic LEDbulbs


Photometric data

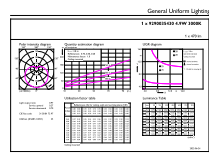


General uniform lighting - CorePro LEDbulb ND 4.9-40W A60 B22 930UK

General uniform lighting - CorePro LEDbulb ND 4.9-40W A60 B22 930UK

Lifetime

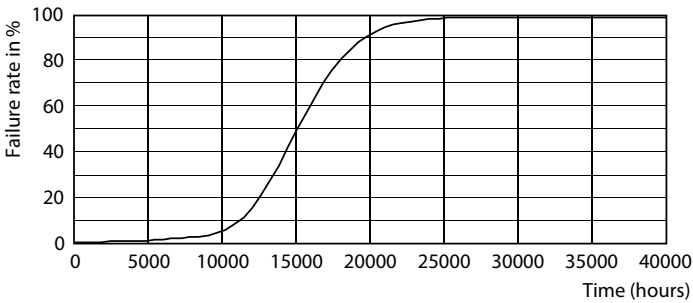

Life Expectancy Diagram - CorePro LEDbulb ND 4.9-40W A60 B22 930UK

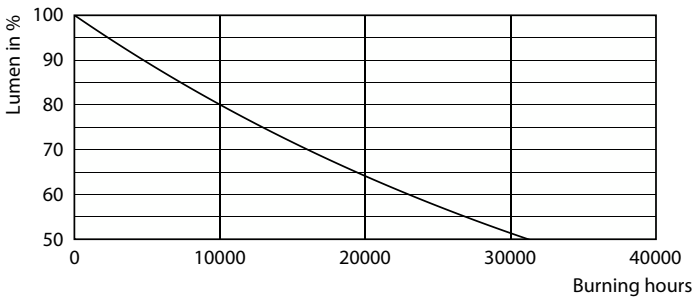

Lumen Maintenance Diagram - CorePro LEDbulb ND 4.9-40W A60 B22 930UK

