

Data sheet Actuator.


Part No.: 02-619.011

Technical data



Design	flush
Mounting cut-out	21.2 mm x 29.2 mm
Terminal	Screw terminal
Operating Travel	ca. 5 mm
Lens illumination	illuminative
Front bezel colour	Black
Front bezel material	Plastic
Housing colour	Black
Housing material	Plastic
Weight	0.055 kg
IP Protection	IP40 front side, IP65 with spray cover, according to IEC 60529
Contact material	Silver
Switching action	Maintained
Switching system	Snap-action switching element
Switching rating	400 V @ 10 A
Contacts	2 C
Operating temperature	- 25 °C ... + 55 °C, mounted as a block, make sure the heat can escape freely
Approbations	CB (IEC 60947-5-1), CENELEC CCA-NTR (EN 60947-5-1), CSA, DNV, SEV, UL
Operating force	6 ... 12 N
Mechanical lifetime	1 Mio. cycles of operation
Tightening torque	Fixing nut max. 0.2 Nm, Screw terminal 0.8 Nm

Dimension drawings

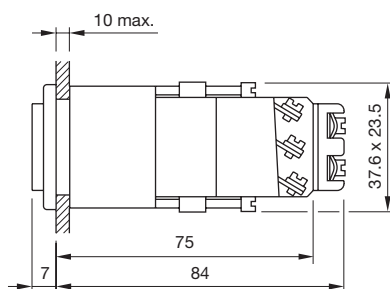

Mounting cut-outs

