

# Data sheet Actuator.


## Part No.: 51-378.F22D

### Technical data




Design	raised
Front dimension	Ø 18 mm
Terminal	Plug-in terminal, 2.8 x 0.5 mm
Weight	0.025 kg
IP front protection	IP65, according to DIN EN 60529
Contact material	Gold
Switching action	Maintained (a) - Rest (a) - Momentary
Rotary positions	3
Switching system	Snap-action switching element
Switching angle	90° left / 42° right
Switching rating	250 V @ 5 A
Contacts	2 NC / 2 NO
Operating temperature	- 25 °C ... + 55 °C
Approbations	CB (IEC 61058-1), CQC, CSA, DNV, ENEC (EN 61058-1), UL
Mechanical lifetime	50 000 cycles of operation
Tightening torque	Fixing nut max. 0.5 Nm
Hints	
	<ul style="list-style-type: none"> <li>▪ Standard lock: DOM 311</li> </ul>

### Dimensions

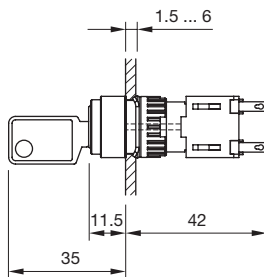


### Mounting cut-outs

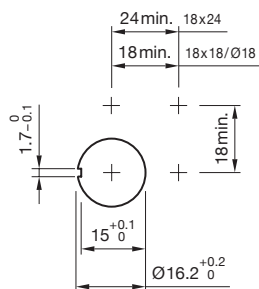

## Wiring diagrams

---

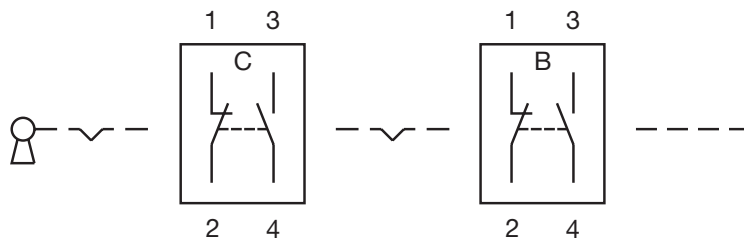

## Switching positions

---

