


PXM0609NSANBK6883 Datasheet

Product Name // Black Anodised Aluminium Plug
Connector - Cable Entry: 6.88-8.38mm

 [View Product Page](#)

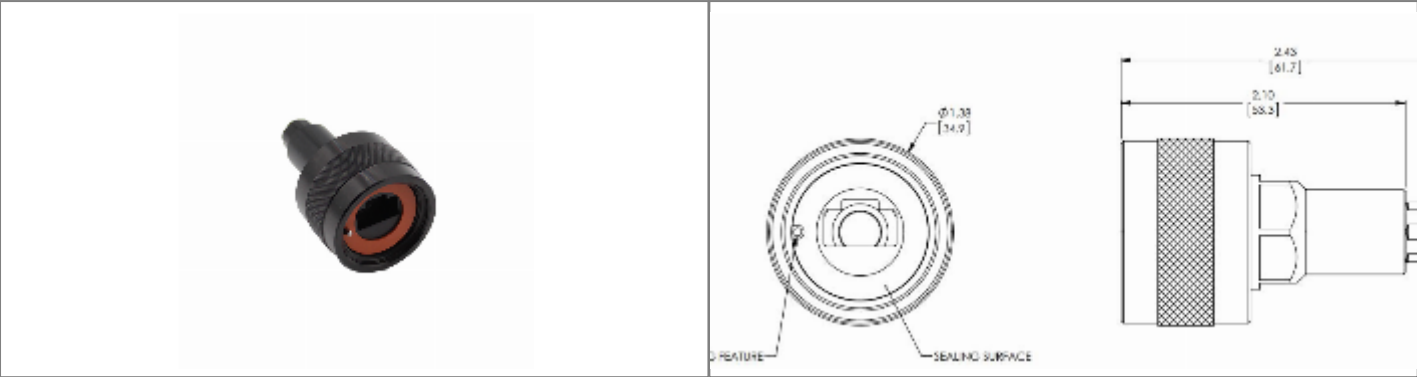

// Product Description:

- Black Anodised Aluminium Plug Connector - Cable Entry: 6.88-8.38mm
- IP68 rated when mated
- Crimp Terminals
- Durability >500 cycles
- Operating temperature -40Â°C to +100Â°C
- Supports 10, 100 and 1,000 Mbps data transmissions
- POE, POE+, and POE++
- Hardware: Stainless Steel, Seals: Silicone

// General Information:

Product Display Title:	Black Anodised Aluminium Plug Connector - Cable Entry: 6.88-8.38mm
Product Family:	Circular Data Connectors
Product Series:	600 Series - Ethernet Buccaneer Connectors
Body Colour:	Black
Body Length:	61.7mm
Body Material:	Aluminium
Body Material Type:	Metal Body
Connection Method:	Standard RJ45 cable to be sourced
Contact Type:	Male
Coupling Type:	Screw
Diameter Over Coupling Ring Mm:	35mm
Durability:	>500 cycles
Ethernet Category:	Any
Function:	Plug Connector
Ip Rating:	IP68
Material Finish:	Anodised
Max Cable Entry Size:	8.38mm
Min Cable Entry Size:	6.88mm
Min Operating Temperature:	-40°C
Operating Humidity:	43°C - 98%
Max Operating Frequency:	+100°C
Rohs Compliant:	Yes
Salt Spray Corrosion Test:	500hr
Shock Resistance:	100G - 6ms

// Product PDF Links

 [Standard Series USB connectors...](#)

// Product 3D CAD Model Links

 [PXM0609NSANBK68833D CAD Model](#)