


Product Code: VPSC520WH

Description: 10A Ingot 3 Pole Fan Isolation Plate Switch

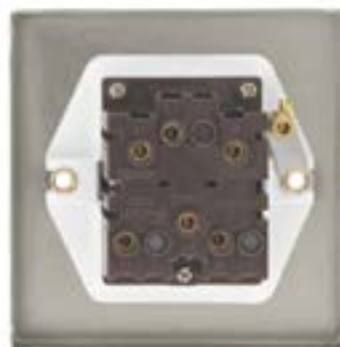

General Information

Plate Dimensions (mm)	88 (W) x 88 (H) x 8 (D)	
Dimensions With Gasket (mm)	91 (W) x 91 (H) x 9 (D)	
Plate Fixing Centres - Horizontal (mm)	60.3	
Style	Victorian	
Finish	Satin Chrome	
Insert Colour	White	
Gasket Colour	White	
Materials	Front Plate: Stainless Steel Switch Cover: Stainless Steel Terminal Screws: Steel & Yellow Passivated Internal Busbars: Formed Pressed Brass Gasket: Nylon	Insert: Urea Terminals: Brass Contacts: Silver "on-lay" Copper / Brass Earth Strap: Mild Steel
Anti Microbial Certified	No	
Rated Voltage (V~) (Ue)	250	Frequency (Hz) 50
Resistive Load Rating (A)	10	
Termination Type	Screw	
Terminal Size (mm)	Ø3.5	Terminal Torque Value (Nm) 0.5
Terminal Capacity - Solid (mm²)	4 x 1.5 or 2 x 2.5	
Modular Rocker Switches	No	
Triple Pole Switch	Yes	
Product Marking	Isolator, On, Off	
Minimum Back Box Depth (mm)	16	
Ingress Protection	IP20	
Operational Temperature (°C)	-5 to +40	
Warranty (Years)	10	

Standards	BS EN 60669-2-4 BS EN 60669-1
------------------	----------------------------------

Additional Information

For cleaning / polishing of products, use only a soft, dry, clean cloth.
Ensure that the mains supply is isolated before commencing installation and refer to the circuit diagram with the relevant product.
Bare earth cables must always be covered with appropriate sleeving and wired to the earth terminal.