



CorePro GLASS LED candles and lustres



CorePro LEDCandleND2-25W E14BA35 827CL G

Featuring a classic heritage design, these filament LED candles combine the familiar shapes of classic incandescent bulbs with the benefits of long-lasting LED technology. The LED candle bulb is a very easy choice for people who are looking for a retrofit LED replacement, it provides 90% energy savings compared with conventional lamps. CorePro Glass LED bulbs provide excellent quality of light for stairway lighting. The LED candle bulb offers a lifetime of 15,000 hours to reduce maintenance costs.

Product data

General information	
Lighting Technology	LED
Flux measurement reference	Sphere
Switching Cycle	20,000
Nominal lifetime	15,000 h
Cap base	E14 [E14]
Light technical	
Colour Code	827 [CCT of 2700K]
Luminous Flux	250 lm
Colour designation	Warm White (WW)
Correlated Colour Temperature	2700 K
Luminous Efficacy (rated) (Nom)	125.00 lm/W
Colour consistency	<6
Colour rendering index (CRI)	80
LLMF at end of nominal lifetime (nom.)	70 %
Flickering value (PstLM)	1

Stroboscopic effect	0.4
Operating and electrical	
Line Frequency	50 to 60 Hz
Input frequency	50 to 60 Hz
Power Consumption	2 W
Lamp current (nom.)	20 mA
Wattage equivalent	25 W
Starting time (nom.)	0.5 s
Warm-up time to 60% light	0.5 s
Power Factor (Fraction)	0.4
Voltage (nom.)	220-240 V
Temperature	
T-Case maximum (nom.)	36 °C

CorePro GLASS LED candles and lustres

Controls and dimming	
Dimmable	No
Mechanical and housing	
Lamp Finish	Clear
Bulb shape	BA35
Approval and application	
Energy Efficiency Class	E
Energy-saving product	Yes
Suitable for accent lighting	No
Energy consumption kWh/1,000 hours	2 kWh
EPREL registration number	387361
CE mark	Yes


Dimensional drawing




EU RoHS compliant	Yes
Product data	
Full EOC	871951437759200
Order product name	CorePro LEDCandleND2-25W E14BA35 827CL G
Order code	37759200
SAP numerator – quantity per pack	1
Numerator – packs per outer box	10
Material number (12NC)	929001238492
Full product name	CorePro LEDCandleND2-25W E14BA35 827CL G
EAN/UPC – Case	8719514377608

Product	D	C
CorePro LEDCandleND2-25W E14BA35 827CL G	35 mm	123 mm

Photometric data

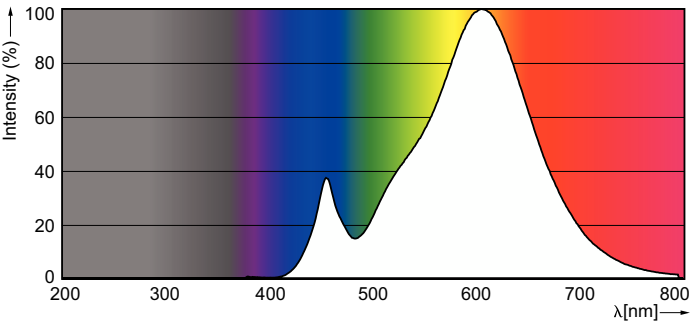


Spectral Power Distribution Colour - CorePro LEDCandleND2-25W E14BA35 827CL G

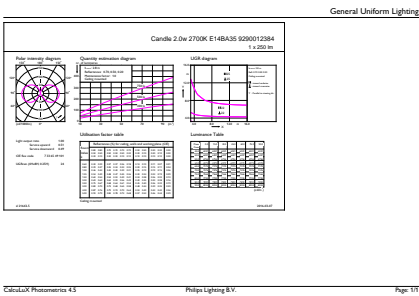

General uniform lighting - CorePro LEDCandleND2-25W E14BA35 827CL G


CorePro GLASS LED candles and lustres

Photometric data

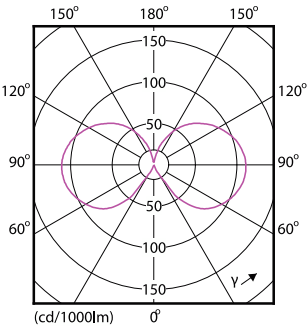


Light Distribution Diagram - CorePro LEDCandleND2-25W E14BA35 827CL G

Lifetime

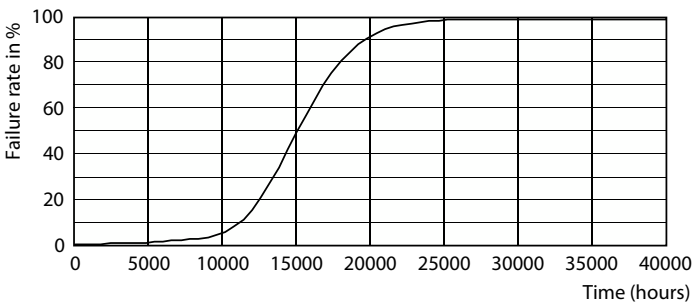

Life Expectancy Diagram - CorePro LEDCandleND2-25W E14BA35 827CL G

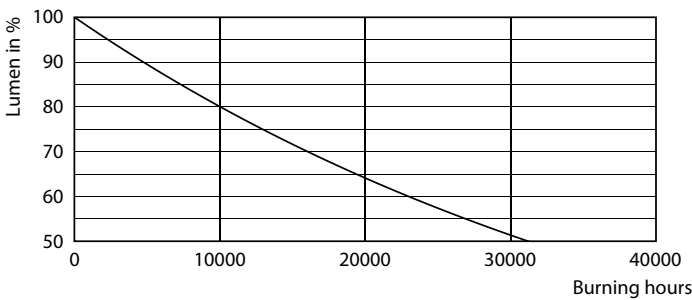

Lumen Maintenance Diagram - CorePro LEDCandleND2-25W E14BA35 827CL G

