


MOTORS

85MM-125MM

OAM82AN-11-1WB, OAM92AN-11-2WB, OAM92AN-11-1WB, OAM97AN-11-1WB,
OAM92AN-22-1WB, OAM105AN-22-1WB, OAM114AN-22-1WB, OAM125AN-22-1WB

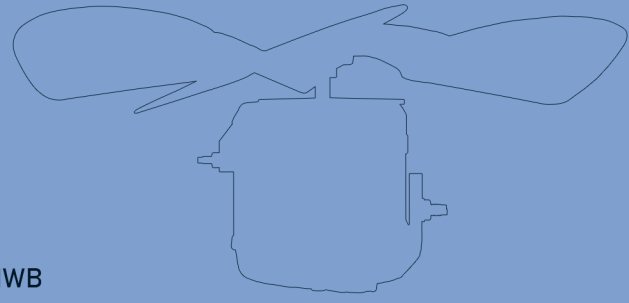

FEATURES AND BENEFITS

- AC AND EC OPEN FRAME MOTORS AVAILABLE
- 115V OR 230V
- 33W-120W
- UL/VDE APPROVED
- BALL BEARINGS
- DIE CAST ALUMINUM
- 3X WIRE LEADS, 500MM LONG
- COMPACT & HIGHLY RELIABLE
- EQUIVALENT TO THE M4Q SERIES
- IMPEDANCE AND THERMAL PROTECTED
- IMPELLERS, GRILLES, AND MOUNTING BRACKETS AVAILABLE



BRACKETS

BRK-55, BRK-72, BRK-84 84, BRK-109-1, BRK-109-2, BRK-109-3

- MATERIAL: GALVANIZED STEEL



GRILLE

FITS IMPELLERS 200MM-250MM
G200-25, G230-27, G250-17

- MATERIAL: STEEL




IMPELLERS

154MM-300MM

IMP-154*, IMP-170*, IMP-200*, IMP-230*,
IMP-250*, IMP-300*

*PITCH ANGLE OPTIONS ARE -19, -22, -25,
-28, -31, AND -34

- MATERIAL: ALUMINUM
- CONNECTION: SET SCREW ON MOTOR SHAFT CONNECTION
- AXIAL IMPELLER
- AIRFLOW DIRECTION: INTAKE (TOWARD MOTOR) IS STANDARD. FOR AIR FLOW AWAY FROM MOTOR (EXHAUST), ADD -R TO END OF PART NUMBER
- BLADE GAUGE: 0.8 ±0.03 MM
- VARIOUS SIZES AND PITCHES AVAILABLE

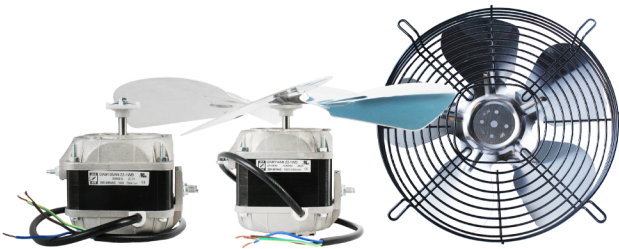

PRODUCT SPECIFICATIONS MAY CHANGE WITHOUT PRIOR NOTIFICATION



ORION FANS

10557 METRIC DR.
DALLAS, TX 75243
214-340-0265
ORIONFANS.COM

