

# PRODUCT DATASHEET

## SMART+ Wifi Planon Plus 600x600mm TW

SMART+ Planon Plus TW | Panel luminaires with WiFi technology



---

### Areas of application

- Indoor applications
- Kitchens, living rooms, children's rooms or home offices

---

### Product benefits

- Easy and quick installation

---

### Product features

- Controllable via LEDVANCE SMART+ WiFi App (with minimum Android™ 4.4 or iOS 10.0)
- Controllable via voice control available: Google Assistant or Amazon Alexa
- Dimmable
- Adjustable color temperature via Tunable White: 3,000...6,500 K
- Network protocol: WiFi



## TECHNICAL DATA

### Electrical data


Nominal wattage	36.00 W
Nominal voltage	220...240 V
Mains frequency	50...60 Hz
Nominal current	200 mA
Power factor $\lambda$	> 0.90
Total harmonic distortion	< 20 %
Protection class	II
Operating mode	Mains voltage

### Photometrical data

Luminous flux	3000 lm
Total luminous flux of contained light sources	3950 lm
Luminous efficacy	83 lm/W
Color temperature	3000...6500 K
Light color (designation)	Tunable White
Color rendering index Ra	$\geq 80$
Standard deviation of color matching	< 6 sdcm
Photobiological safety group acc. to EN62778	RG0
Photobiological safety group acc. to EN62471	RG0
Beam angle	110 °

### Dimensions & Weight

Length	595.00 mm
Width	595.00 mm
Height	56.00 mm
Product weight	3520.00 g

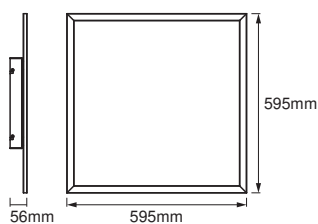

## Materials & Colors

Product color	White
Housing color	White
Body material	Aluminum
Cover material	Polymethylmethacrylate (PMMA)
Light emitting surface material	PMMA
Glow Wire Test according to IEC 60695-2-12	650 °C
Mercury content	0.0 mg

## Application & Mounting

Ambient temperature range	-20...+40 °C
Temperature range at storage	-20...+40 °C
Type of connection	Terminal, 2-Pole (L, N)
Type of protection	IP20
Dimmable	Yes
Type of dimming	WiFi
Mounting type	Surface
Mounting location	Ceiling
Application environment	Indoor
LED module replaceable	Not replaceable
With light source	No

## Lifespan

Lifespan L70/B50 at 25 °C	25000 h
Number of switching cycles	15000

## Certificates & Standards

Standards	CE / EAC / UKCA
Luminaire with limited surface temperature, "D sign"	No

## Additional product data




Product remark	Reset settings to default by switching the product on for three seconds and off for three seconds and repeating this five times. / Available from January 2021
----------------	--

## EQUIPMENT / ACCESSORIES

- Mounting bracket included
- Mounting screws and dowels included
- Control via app or voice control requires compatible Smart home system
- For control via LEDVANCE SMART + WiFi App, a smart phone or Tablet PC is required

---

## DOWNLOAD DATA

Documents and certificates	
	User instruction
	Declarations Of Conformity CE
	Declarations Of Conformity UKCA

---

## LOGISTICAL DATA

Product code	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Gross weight	Volume
4058075525382	Folding box 1	76 mm x 622 mm x 623 mm	4424.00 g	29.45 dm <sup>3</sup>
4058075525399	Shipping box 3	672 mm x 281 mm x 680 mm	13810.00 g	128.41 dm <sup>3</sup>

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

---

## DISCLAIMER

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.