


Product Datasheet

ZINK CARBON

Red Zink



6F22

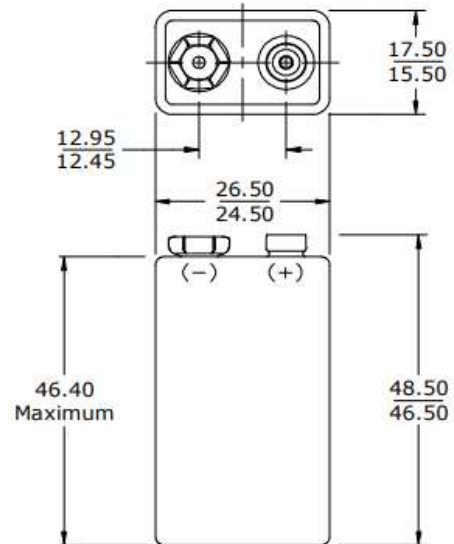


IEC Dimensions (mm)		
Dimension	Maximum	Minimum
H	48,5	46,5
W	26,5	24,5
D	17,5	15,5




Name	R20
Size	9V40,5
Type	Zink carbon
Nominal Voltage	9 V
Made in	China
Average weight	37 g
Internal impedance (after discharge to E.V.=1.0V)	Approx. 10mΩ (at 1000Hz)

Typical characteristics

Storage/Capacity characteristics (at various temperatures)

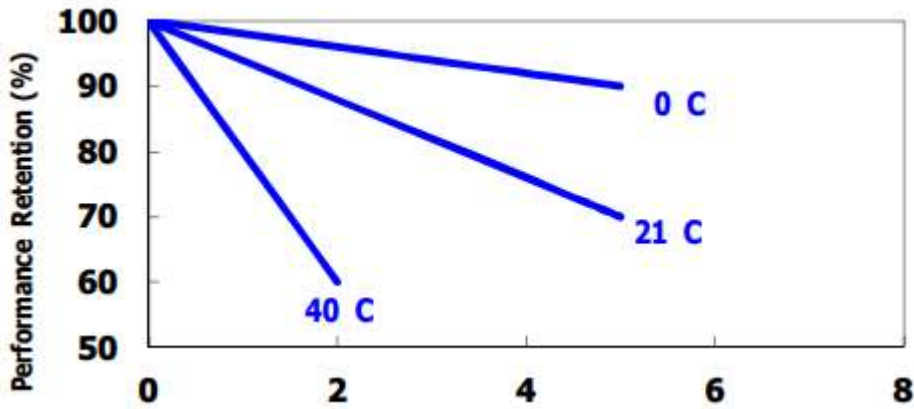

Industry standard test

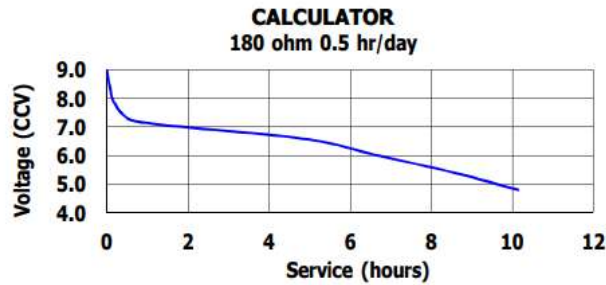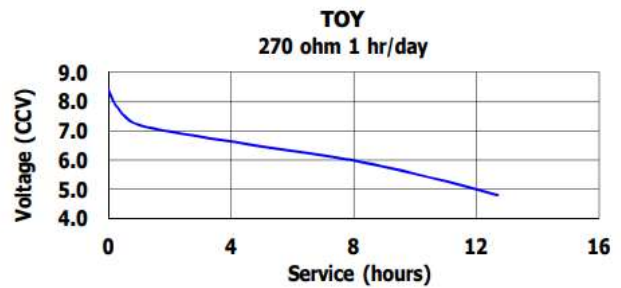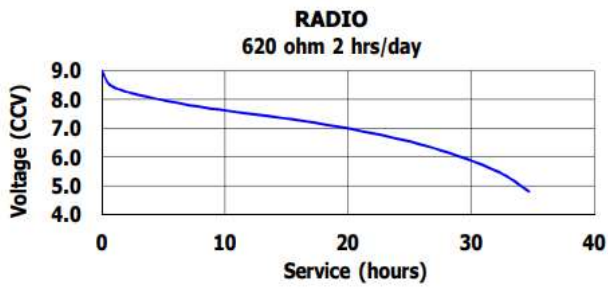

Copyright© Advance Power Solutions NV 2022 — All rights reserved. The information contained herein is believed to be correct. However no warranty is made, either expressed or implied regarding the accuracy or the results to be obtained from the use of such information. Test results are according to IEC conditions. Capacities of batteries are depending on drain, temperature and cut-off voltage. Data are subject to change without prior notification. October 2022.