


Product Datasheet

Zinc-Carbon

R20 (DRNF-E mix grade)



R20

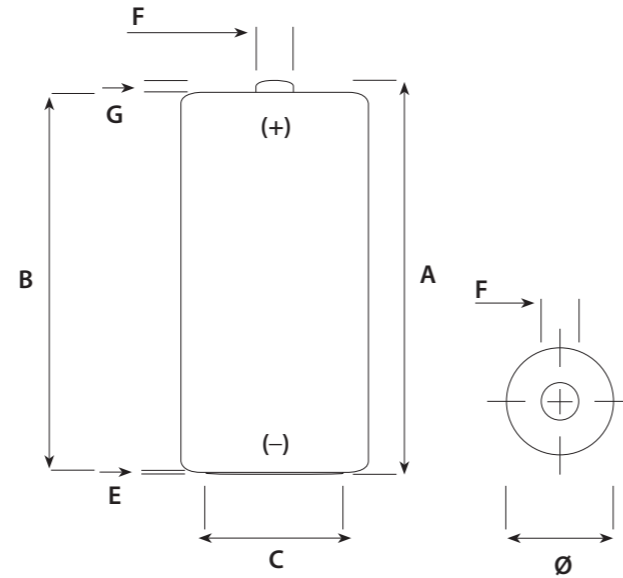

IEC Dimensions (mm)		
Dimension	Maximum	Minimum
A	61,5	
B		59,5
C		18,0
E	1,0	
F	9,5	
G		1,5
Ø	34,2	32,3

Name	R20 / XL / D
Made in	Poland
Type	Carbon Zinc battery
Nominal Voltage	1,5 Volt
Electrolyte	Zinc chloride
Average weight	98,5 g
Storage temperature range	+10°C (50°F) ~ +25°C (77°F)
Operating temperature range	-20°C (-4°F) ~ +45°C (113°F)
Average Impedance	+/- 180 m-Ohm
Heavy metals	No added mercury (Hg), Cadmium (Cd) or Lead (Pb)
Compliant to	IEC 60086 non dangerous goods regulation EU directive 2006/66/EC
Recommended cut off voltage	0,8V per cell

Typical discharge values

R20 DRNF-E grade

