


## Technical Specification

**Product Code:** CMA20508

**Description:** 8 Gang GridPro® Frontplate

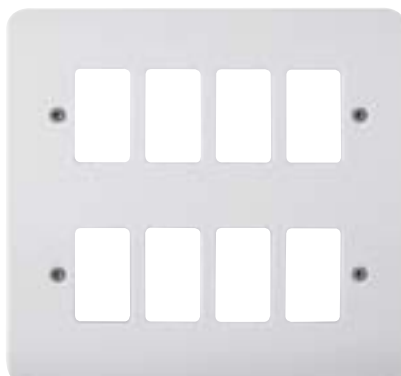

### General Information

|                              |                           |                    |
|------------------------------|---------------------------|--------------------|
| Plate Dimensions (mm)        | 146 (W) x 146 (H) x 9 (D) |                    |
| Style                        | Mode                      |                    |
| Finish                       | Polar White               |                    |
| Materials                    | Front Plate: Urea         | Fixing Lugs: Brass |
| Anti Microbial Certified     | Yes                       |                    |
| Yoke Required                | Yes (2 x GR20400)         |                    |
| Minimum Back Box Depth (mm)  | 47                        |                    |
| Ingress Protection           | IP20                      |                    |
| Operational Temperature (°C) | -5 to +40                 |                    |
| Warranty (Years)             | 10                        |                    |

**Standards** BS 5733

### Additional Information

For cleaning / polishing of products, use only a soft, dry, clean cloth.  
Ensure that the mains supply is isolated before commencing installation and refer to the circuit diagram with the relevant product.  
Bare earth cables must always be covered with appropriate sleeving and wired to the earth terminal.  
All white moulded accessories are manufactured using Urea Formaldehyde, which has similar inherent properties to antimicrobial additives that inhibit the growth of infectious diseases as well as anti-viral properties against enveloped and non-enveloped viruses.  
All products have been independently tested with 99.9% of enveloped viruses and 92% of non-enveloped viruses killed off whilst achieving a 99.9% kill rate across all four types of the strains of bacteria - MRSA, E-Coli, Salmonella, and Klebsiella Pneumoniae.