

# Product data sheet

Specifications



Contactor, Definite Purpose, 50A, 3 pole, 30 HP at 575 VAC, 3 phase, 110/120 VAC 50/60 Hz coil, open

8910DPA53V02

Product availability : Stock - Normally stocked in distribution facility

## Main

Product or Component Type	Definite Purpose Contactor
Line Rated Current	50 A
Number of Poles	3P
Pole contact composition	3 NO
Range of Product	DPA

## Complementary

Maximum Horse Power Rating	3 hp 115 V AC, 1 phase 10 hp 230 V AC, 1 phase 15 hp 230 V AC, 3 phase 30 hp 460 V AC, 3 phase 30 hp 575 V AC, 3 phase
Locked rotor rated current	300 A 277 V AC 250 A 460 V AC 200 A 575 V AC
[Ue] rated operational voltage	600 V AC
[Uc] control circuit voltage	120 V AC 60 Hz 110 V AC 50 Hz
Phase	3 phase
Electrical Connection	Box lugs Quick connect terminals
Height	4.13 in (104.90 mm) 4.13 in (105 mm)
Width	2.56 in (65.02 mm) 2.56 in (65 mm)
Depth	3.67 in (93.22 mm) 3.66 in (93 mm)
Net Weight	1.50 lb(US) (0.68 kg) 1.5 lb(US) (0.68 kg)

## Environment

Product Certifications	UL Recognized CSA
------------------------	----------------------

## Ordering and shipping details

Category	21345-8910 DPA 5_(50 AMP)
Discount Schedule	CP1B

GTIN	785901080756
Returnability	Yes
Country of origin	CN

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	3.70 in (9.398 cm)
Package 1 Width	2.80 in (7.112 cm)
Package 1 Length	4.50 in (11.43 cm)
Package 1 Weight	24.00 oz (680.389 g)


Offer Sustainability

REACH Regulation	<a href="#">REACH Declaration</a>
EU RoHS Directive	Compliant <a href="#">EU RoHS Declaration</a>
Mercury free	Yes
China RoHS Regulation	<a href="#">China RoHS declaration</a> Product out of China RoHS scope. Substance declaration for your information.
RoHS exemption information	<a href="#">Yes</a>

Contractual warranty

Warranty	18 months
----------	-----------

Approximate Dimensions

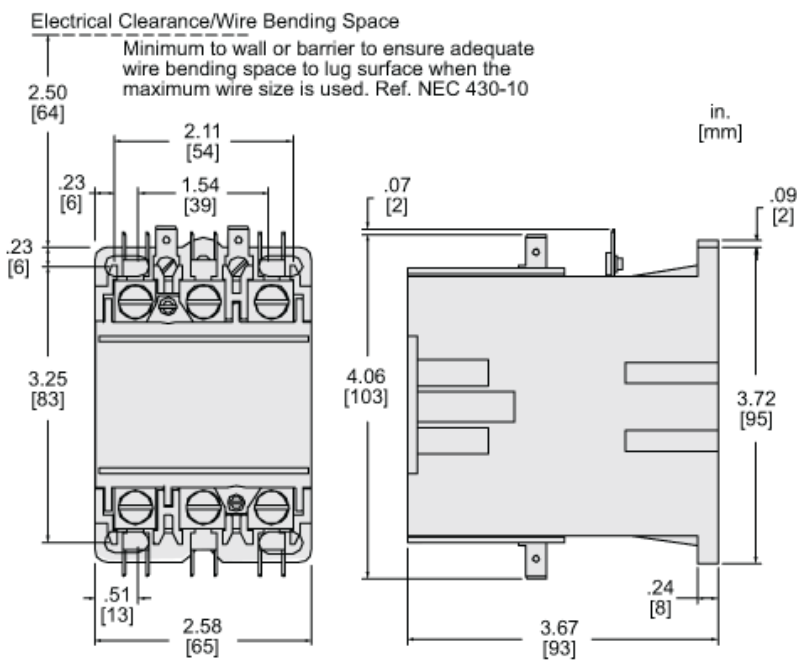

Recommended replacement(s)