


Product Code: QCGM32BLK

Description: 32mm Nylon Glands - Black

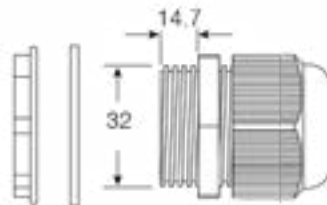

Dimensions

Spanner Size (mm)	42
Threaded Diameter (mm)	32
Threaded Entry Length (mm)	14.7

General Information

Colour	Black
Cable Clamping Range (mm)	18 - 25
Recommended Cap Tightening Torque (Nm)	3.0 - 4.0
Ingress Protection	IP68
Temperature Rating (°C)	0 to +80

Materials

Gland Body: Nylon 66
Seal: TPE (Thermoplastic Elastomer)
Washer: PVC (Polyvinyl Chloride)

Standards

ANSI/UL 514B
BS EN 60529: 1992 + A2: 2013

