


Product Code: QCGM40WHT

Description: 40mm Nylon Glands - White

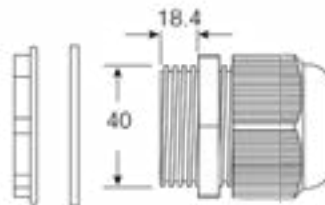

Dimensions

Spanner Size (mm)	53
Threaded Diameter (mm)	40
Threaded Entry Length (mm)	18.4

General Information

Colour	White
Cable Clamping Range (mm)	22 - 32
Recommended Cap Tightening Torque (Nm)	4.0 - 5.0
Ingress Protection	IP68
Temperature Rating (°C)	0 to +80

Materials

Gland Body: Nylon 66
Seal: TPE (Thermoplastic Elastomer)
Washer: PVC (Polyvinyl Chloride)

Standards

ANSI/UL 514B
BS EN 60529: 1992 + A2: 2013