


Product Code: QCGM63WHT

Description: 63mm Nylon Glands - White

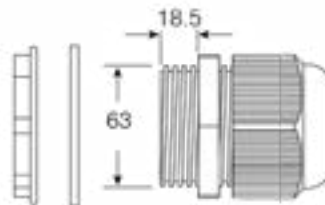

Dimensions

Spanner Size (mm)	75
Threaded Diameter (mm)	63
Threaded Entry Length (mm)	18.5

General Information

Colour	White
Cable Clamping Range (mm)	34 - 44
Recommended Cap Tightening Torque (Nm)	6.0 - 7.0
Ingress Protection	IP68
Temperature Rating (°C)	0 to +80

Materials

Gland Body: Nylon 66
Seal: TPE (Thermoplastic Elastomer)
Washer: Natural Rubber

Standards

ANSI/UL 514B
BS EN 60529: 1992 + A2: 2013