


Category 6A 0.5U 24 Port Patch Panel:

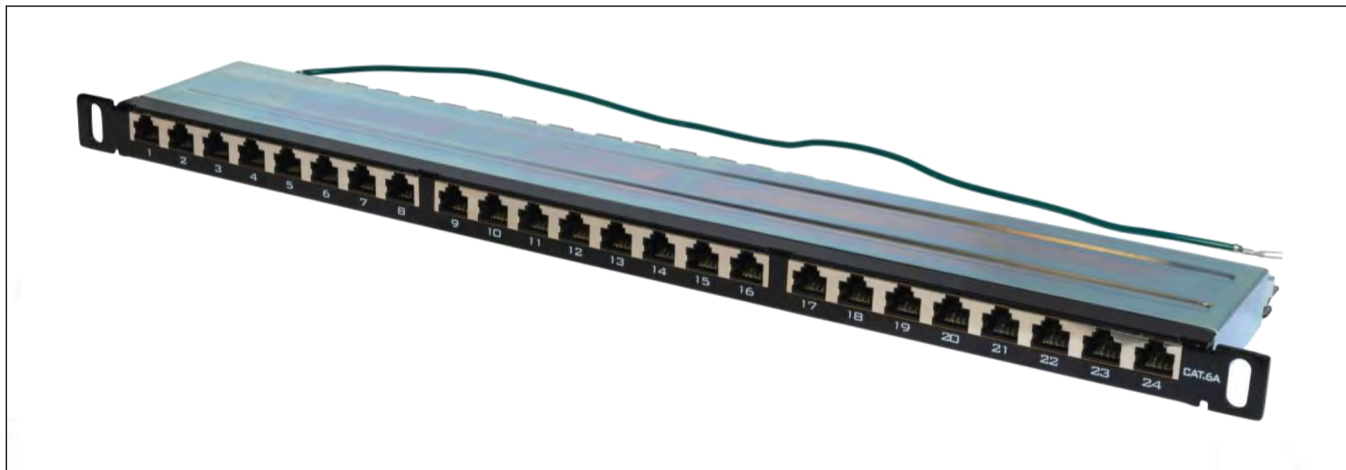

Category 6A 0.5U 24 Port Patch Panel (SGF24mc0.5):

TUK's horizontal 0.5U Category 6A FTP patch panel offers high performance, very high density and a competitive price. Connections are industry standard LSA+ type and are conveniently arranged horizontally to provide flexible cable management and space saving.

Features:

- Performs to Category 6A standards (permanent link level)
- 0.5U construction enables double the space efficiency of standard panels with virtually no difference in termination time
- Robust and high quality metal construction
- Integral "tray type" horizontal IDC's for ease of termination, with 'offset' arrangement to minimise crosstalk
- Accommodates LSA+ type termination tools
- Clear labelling for T568B wiring
- Supplied with cage nut set, cable ties and earth lead

Specifications:

- Net weight (including primary packaging): 1288g
 - Dimensions: 482.6 x 116.9 x 22.23 mm
With outer packaging: 525 x 148 x 33mm Carton of 6: 540 x 180 x 320mm
 - Colour: Black and silver
-



- Electrical specifications:
Current rating: 1.5A
Dielectric withstanding voltage: 1000VAC 60Hz
Insulation resistance: 500M Ω min.
Contact resistance: 20m Ω max.
- Materials:
RJ45 jack contacts: 50 μ "/1.27 μ m gold plated phosphor bronze
Frame: Cold rolled steel

Packaging: Product supplied in individual carton then in cartons of 6

Commodity code: 85177090

EAN: 5055386511034

Country of Origin: China

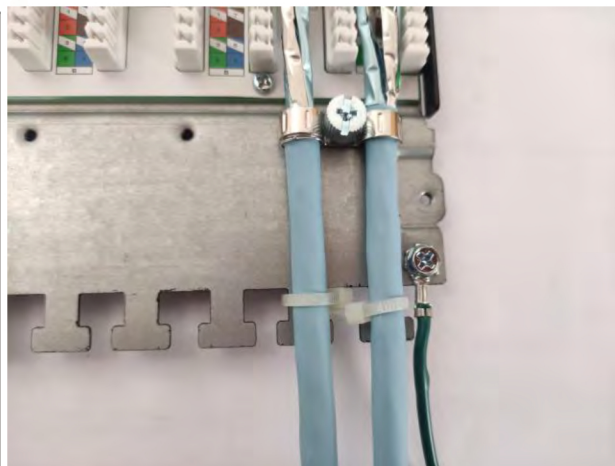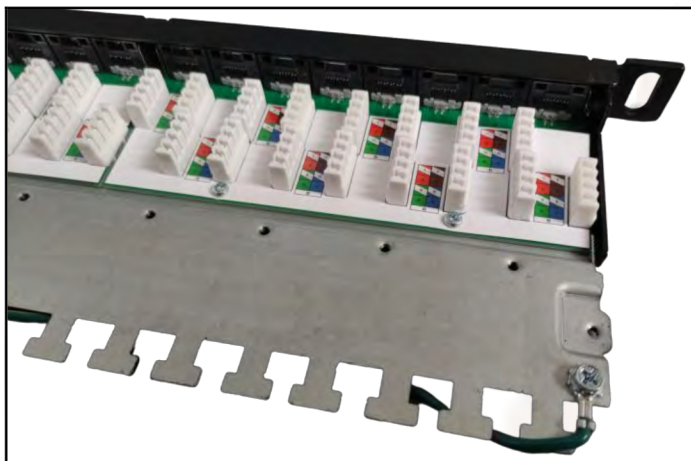

Illustrative images