


AD+Sign DS-1

Digital Signage Player



Specification Sheet

The Ad-Sign DS-1 is a powerful digital signage player combining a small form-factor footprint with DemoPad's standalone Ad-Sign mobile app. Flexible, customisable media can be deployed locally or via online resources, quickly providing striking visual content on any digital display or TV. Perfect for commercial applications, the DS-1 can integrate image slideshows, local HDMI sources, network media, and live messages to create a fully-complete, professional Digital Signage experience.

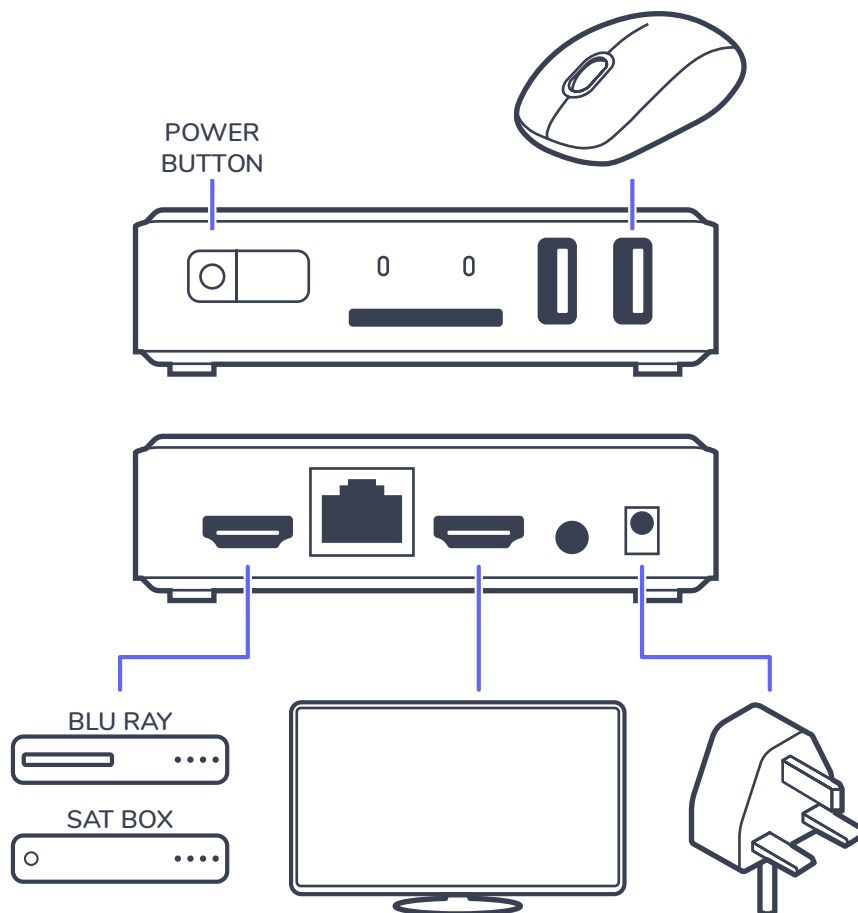

Key Features

- Stunning 4K media on Display
- Discrete size fits behind equipment
- Live messages and alerts
- Offline capability, internet redundancy mode
- Local HDMI video overlay / PIP
- Useful, time-saving design templates

Package Contents

- DS-1 Digital Signage Player
- 1x 5V/2A DC Power Supply
- Power Supply plug adaptors
- 1x HDMI Cable

For instructions on how to get started, visit ad-sign.tv/docs



Audio and Video

Output Connections	1x HDMI 19-pin type A port
Output Formats	HDMI: Video up to 4K60 3840x2160p*
	HDMI: All supported audio formats including PCM & bitstream codecs
Input Connections	1x HDMI 19-pin type A port
Input Formats	HDMI: Video up to 2K60 1920x1080p

Peripheral Interfaces

USB	1x USB 2.0 type A host port
	1x USB 3.0 type A Super Speed host port
Memory Card	1x SD Card receptacle (SDXC card compatible)

Communication & Control

Networking	Dual-band WiFi: IEEE 802.1ac 2.4GHz and 5GHz
	Gigabit Ethernet: IEEE 802.1ab 1000Base-T (backwards compatible)

Power

Power Supply	5V/2.5A DC
Power Consumption	8W

Dimensions & Weight

Dimensions	61mm [W] x 29mm [D] x 92mm [H]
Weight (net)	193g

Environmental

Operating Temperature	-0 - 50°C
Storage Temperature	-10 - 60°C
Relative Humidity	0% - 80%
Maximum BTU	23.9 BTU/h

Regulatory

Safety & Emission	CE, FCC
-------------------	---------

*4K60 uses YCBCR 4:2:0 pixel encoding.