


POLYESTER BOXES – RAL7035

IP66

Plain door / glazed door. Multiple choice accessories.


POLYESTER BOXES

- 7 Standard dimensions with plain door and glazed door
- Heavy duty glass reinforced polyester
- Multiple choice of accessories. Easy install, only screwdriver required to install
- IP66 for all models
- Lightweight material makes handling easier and reduces shipping cost
- Low solar heat absorption.
Operating temperature -25 to +60 Degrees
- High impact strength and rigidity.

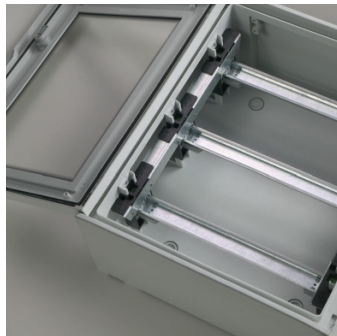


Polyester hinged door enclosures provide outstanding protection and conform to IP66 protection both for plain door and glazed door variations. Polyester enclosures offer rugged durability in the most demanding of environments. Manufactured from high quality glass reinforced polyester and available in 7 popular dimensions with plain door and glazed door. A host of easy to install accessories are available that require only a screwdriver to install. An integral drip shield directs liquids away from the door seal.

Need machining? Customised polyester enclosures from Spelsberg are now available with minimum lead times. OEM's and contractors alike can save time and money with access to a fast prototype service and facility to order ready modified enclosures. This new milling / drilling service offers custom cable entries as well as holes and cut-outs on all surfaces.

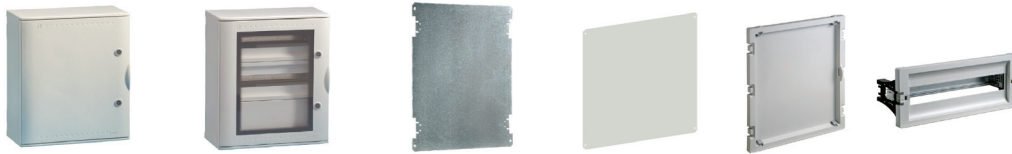

Dimensions WxHxD	Ordering Code Plain Door	Ordering Code Glazed Door	Metal MTG Plate	Polyester MTG Plate	Inner Door	Mounting Panel with slot	No. of Modules
265x300x165	159 500 S1	159 520 S1	159 100 S1	159 200 S1			
325x425x180	159 501 S1	159 521 S1	159 101 S1	159 201 S1	159 120 S1	159 140 S1	3 Rows x 12
430x500x210	159 502 S1	159 522 S1	159 102 S1	159 202 S1	159 121 S1	159 141 S1	3 Rows x 18
430x650x210	159 503 S1	159 523 S1	159 103 S1	159 203 S1	159 122 S1	159 141 S1	4 Rows x 18
540x650x260	159 504 S1	159 524 S1	159 104 S1	159 204 S1	159 123 S1	159 142 S1	4 Rows x 24
615x805x315	159 505 S1	159 525 S1	159 105 S1	159 205 S1	159 124 S1	159 143 S1	5 Rows x 28
810x1060x355	159 506 S1	159 526 S1	159 106 S1		159 125 S1	159 144 S1	5 Rows x 38

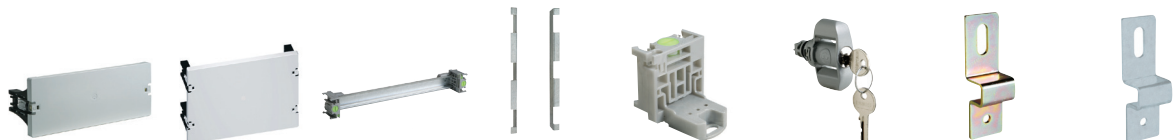

Dimensions WxHxD	Modular Panel Blank	Modular Panel Double Blank	Din Rail Assembly	Din Rail Frame Assembly	Plate Adjustment Brackets (1)	Key Lock	Wall Brackets Galvanised *	Wall Brackets Stainless *
265x300x165						159 090 S1	159 095 S1	159 096 S1
325x425x180	159 130 S1	159 151 S1	159 160 S1	159 170 S1	159 094 S1	159 090 S1	159 095 S1	159 096 S1
430x500x210	159 131 S1	159 152 S1	159 161 S1	159 171 S1	159 094 S1	159 090 S1	159 095 S1	159 096 S1
430x650x210	159 131 S1	159 152 S1	159 161 S1	159 172 S1	159 094 S1	159 090 S1	159 095 S1	159 096 S1
540x650x260	159 132 S1	159 153 S1	159 162 S1	159 172 S1	159 094 S1	159 090 S1	159 095 S1	159 096 S1
615x805x315	159 133 S1	159 154 S1	159 163 S1	159 173 S1	159 094 S1	159 090 S1	159 095 S1	159 096 S1
810x1060x355	159 134 S1	159 150 S1	159 164 S1	159 174 S1	159 094 S1	159 090 S1	159 095 S1	159 096 S1