

Through Terminal Block, Ground Conductor Terminal Block, Double-Potential Terminal Block TOPJOB® S; with Push-Button 2.5 (4) mm²; 2202 Series

1

Technical Data

0.25 ... 2.5 (4) mm ² ①	22 ... 12 AWG
800 V / 8 kV / 3 ②	600 V, 20 A ③
I _N 24 A (32 A)	600 V, 20 A ④

Terminal block width: 5.2 mm / 0.205 inch

 10 ... 12 mm / 0.39 ... 0.47 inch

Technical Data

0.25 ... 2.5 (4) mm ² ①	22 ... 12 AWG
800 V / 8 kV / 3 ②	600 V, 20 A ③
I _N 24 A (32 A)	600 V, 20 A ④

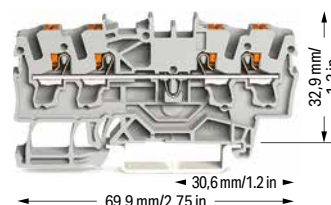
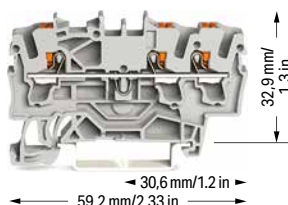
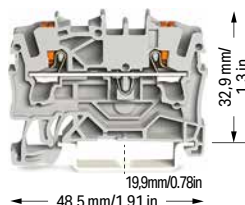
Terminal block width: 5.2 mm / 0.205 inch

 10 ... 12 mm / 0.39 ... 0.47 inch

Technical Data

0.25 ... 2.5 (4) mm ² ①	22 ... 12 AWG
800 V / 8 kV / 3 ②	600 V, 20 A ③
I _N 24 A (32 A)	600 V, 20 A ④

Terminal block width: 5.2 mm / 0.205 inch

 10 ... 12 mm / 0.39 ... 0.47 inch


2-conductor through terminal block; with push-button

Color	Item No.	Pack. Unit
gray ⑤	2202-1201 ④	100
blue ⑤	2202-1204 ③ ④	100
orange ⑤	2202-1202 ④	100
red ⑤	2202-1203 ④	100
black ⑤	2202-1205 ④	100
yellow ⑤	2202-1206 ④	100
black ⑤	2202-1209 ④	100

3-conductor through terminal block; with push-button

Color	Item No.	Pack. Unit
gray ⑤	2202-1301 ④	100
blue ⑤	2202-1304 ③ ④	100
orange ⑤	2202-1302 ④	100
red ⑤	2202-1303 ④	100
black ⑤	2202-1305 ④	100
yellow ⑤	2202-1306 ④	100
black ⑤	2202-1309 ④	100

4-conductor through terminal block; with push-button

Color	Item No.	Pack. Unit
gray ⑤	2202-1401 ④	100
blue ⑤	2202-1404 ③ ④	100
orange ⑤	2202-1402 ④	100
red ⑤	2202-1403 ④	100
black ⑤	2202-1405 ④	100
yellow ⑤	2202-1406 ④	100
black ⑤	2202-1409 ④	100

2-conductor ground terminal block; with push-button

green-yellow ⑤	2202-1207 ④	100
----------------	-------------	-----

3-conductor ground terminal block; with push-button

green-yellow ⑤	2202-1307 ④	100
----------------	-------------	-----

4-conductor ground terminal block; with push-button

green-yellow ⑤	2202-1407 ④	100
----------------	-------------	-----

Accessories; item-specific

End and intermediate plate; 0.8 mm thick

	orange	2002-1292	100 (25)
	gray	2002-1291	100 (25)

Accessories; item-specific

End and intermediate plate; 0.8 mm thick

	orange	2002-1392	100 (25)
	gray	2002-1391	100 (25)

Accessories; item-specific

End and intermediate plate; 0.8 mm thick

	orange	2002-1492	100 (25)
	gray	2002-1491	100 (25)

Separator; oversized; 2 mm thick

	orange	2002-1294	100 (25)
	gray	2002-1293	100 (25)

Separator; oversized; 2 mm thick

	orange	2002-1394	100 (25)
	gray	2002-1393	100 (25)

Separator; oversized; 2 mm thick

	orange	2002-1494	100 (25)
	gray	2002-1493	100 (25)

Ex e/Ex i separator; orange; 3 mm thick

	90 mm	209-190	50 (25)
	120 mm	209-191	50 (25)

Ex e/Ex i separator; orange; 3 mm thick

	120 mm	209-191	50 (25)
---	--------	---------	---------

Ex e/Ex i separator; orange; 3 mm thick

	120 mm	209-191	50 (25)
---	--------	---------	---------

Accessories; 2202 Series

Appropriate marking systems: WMB/WMB Inline/Marking strips

Insulation stop; 5 pcs/strip; 0.25 ... 0.5 mm²

	light gray	2002-171	200 (25)
---	------------	----------	----------

Insulation stop; 5 pcs/strip; 0.75 ... 1 mm²

	dark gray	2002-172	200 (25)
---	-----------	----------	----------

Push-in type jumper bar; insulated; I_N 25 A; light gray

	2-way	2002-402	25
	3-way	2002-403	25
	4-way	2002-404	25
	5-way	2002-405	25
	6-way	2002-406	25
	7-way	2002-407	25
	8-way	2002-408	25
	9-way	2002-409	25
	10-way	2002-410	25

Push-in type jumper bar; insulated; I_N 25 A; light gray

	1 to 3	2002-433	25
	1 to 4	2002-434	25
	1 to 5	2002-435	25
	1 to 6	2002-436	25
	1 to 7	2002-437	25
	1 to 8	2002-438	25
	1 to 9	2002-439	25
	1 to 10	2002-440	25

Delta jumper; insulated; I_N = I_N terminal block; light gray

	1-2 3-4 5-6	2002-406/020-000	25
---	-------------	------------------	----

Star point jumper; insulated; I_N = I_N terminal block; light gray

	1-3-5	2002-405/011-000	25
---	-------	------------------	----

Continuous jumper; insulated; I_N 25 A; light gray

	2-way	2002-400	25
---	-------	----------	----

Continuous jumper; insulated; I_N 25 A; light gray

	1 to 3	2002-423	25
	1 to 4	2002-424	25

Continuous jumper; insulated; I_N 25 A; light gray

	3-way	2002-413	25
	5-way	2002-415	25

Staggered jumper; insulated; I_N 25 A; light gray

	2-way	2002-472	25
	3-way	2002-473	25
	4-way	2002-474	25
	5-way	2002-475	25
	6-way	2002-476	25
	7-way	2002-477	25
	8-way	2002-478	25
	9-way	2002-479	25
	10-way	2002-480	25
	11-way	2002-481	25
	12-way	2002-482	25