

Through Terminal Block, Ground Conductor Terminal Block TOPJOB® S; with Push-Button 4 (6) mm²; 2204 Series

1

Technical Data

0.5 ... 4 (6) mm ² ①	20 ... 10 AWG
800 V / 8 kV / 3 ②	600 V, 30 A ③
I _N 32 A (41 A)	600 V, 30 A ④

Terminal block width: 6.2 mm / 0.244 inch

 11 ... 13 mm / 0.43 ... 0.51 inch

Technical Data

0.5 ... 4 (6) mm ² ①	20 ... 10 AWG
800 V / 8 kV / 3 ②	600 V, 30 A ③
I _N 32 A (41 A)	600 V, 30 A ④

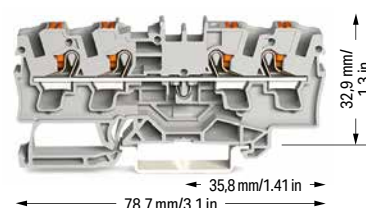
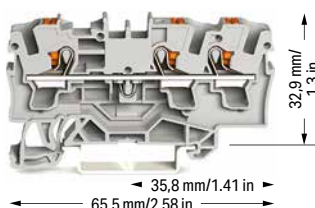
Terminal block width: 6.2 mm / 0.244 inch

 11 ... 13 mm / 0.43 ... 0.51 inch

Technical Data

0.5 ... 4 (6) mm ² ①	20 ... 10 AWG
800 V / 8 kV / 3 ②	600 V, 30 A ③
I _N 32 A (41 A)	600 V, 30 A ④

Terminal block width: 6.2 mm / 0.244 inch

 11 ... 13 mm / 0.43 ... 0.51 inch


2-conductor through terminal block; with push-button

Color	Item No.	Pack. Unit
gray ⑤	2204-1201 ④	50
blue ⑤	2204-1204 ③ ④	50
orange ⑤	2204-1202 ④	50
red ⑤	2204-1203 ④	50
black ⑤	2204-1205 ④	50
yellow ⑤	2204-1206 ④	50
light gray ⑤	2204-1209 ④	50

3-conductor through terminal block; with push-button

Color	Item No.	Pack. Unit
gray ⑤	2204-1301 ④	50
blue ⑤	2204-1304 ③ ④	50
orange ⑤	2204-1302 ④	50
red ⑤	2204-1303 ④	50
black ⑤	2204-1305 ④	50
yellow ⑤	2204-1306 ④	50
light gray ⑤	2204-1309 ④	50

4-conductor through terminal block; with push-button

Color	Item No.	Pack. Unit
gray ⑤	2204-1401 ④	50
blue ⑤	2204-1404 ③ ④	50
orange ⑤	2204-1402 ④	50
red ⑤	2204-1403 ④	50
black ⑤	2204-1405 ④	50
yellow ⑤	2204-1406 ④	50
light gray ⑤	2204-1409 ④	50

2-conductor ground terminal block; with push-button

green-yellow ⑤	2204-1207 ④	50
----------------	-------------	----

3-conductor ground terminal block; with push-button

green-yellow ⑤	2204-1307 ④	50
----------------	-------------	----

4-conductor ground terminal block; with push-button

green-yellow ⑤	2204-1407 ④	50
----------------	-------------	----

Accessories; item-specific

End and intermediate plate; 1 mm thick

	orange	2004-1292	100 (25)
	gray	2004-1291	100 (25)

Accessories; item-specific

End and intermediate plate; 1 mm thick

	orange	2004-1392	100 (25)
	gray	2004-1391	100 (25)

Accessories; item-specific

End and intermediate plate; 1 mm thick

	orange	2004-1492	100 (25)
	gray	2004-1491	100 (25)

Separator; oversized; 2 mm thick

	orange	2004-1294	100 (25)
	gray	2004-1293	100 (25)

Separator; oversized; 2 mm thick

	orange	2004-1394	100 (25)
	gray	2004-1393	100 (25)

Separator; oversized; 2 mm thick

	orange	2004-1494	100 (25)
	gray	2004-1493	100 (25)

Ex e/Ex i separator; orange; 3 mm thick

	90 mm	209-190	50 (25)
	120 mm	209-191	50 (25)

Ex e/Ex i separator; orange; 3 mm thick

	120 mm	209-191	50 (25)
---	--------	---------	---------

Ex e/Ex i separator; orange; 3 mm thick

	120 mm	209-191	50 (25)
---	--------	---------	---------

Accessories; 2204 Series

Appropriate marking systems: WMB/WMB Inline/Marking strips

Insulation stop; 5 pcs/strip; 0.25 ... 0.5 mm²

	light gray	2004-171	200 (25)
---	------------	----------	----------

Insulation stop; 5 pcs/strip; 0.75 ... 1 mm²

	dark gray	2004-172	200 (25)
---	-----------	----------	----------

Push-in type jumper bar; insulated; I_N 32 A; light gray

	2-way	2004-402	25
	3-way	2004-403	25
	4-way	2004-404	25
	5-way	2004-405	25
	6-way	2004-406	25
	7-way	2004-407	25
	8-way	2004-408	25
	9-way	2004-409	25
	10-way	2004-410	25

Push-in type jumper bar; insulated; I_N 32 A; light gray

	1 to 3	2004-433	25
	1 to 4	2004-434	25
	1 to 5	2004-435	25
	1 to 6	2004-436	25
	1 to 7	2004-437	25
	1 to 8	2004-438	25
	1 to 9	2004-439	25
	1 to 10	2004-440	25

Star point jumper; insulated; I_N = I_N terminal block; light gray

	1-3-5	2004-405/011-000	25
---	-------	------------------	----

Delta jumper; insulated; I_N = I_N terminal block; light gray

	1-2 3-4 5-6	2004-406/020-000	
---	-------------	------------------	--

Step-down jumper; insulated; commons 6/4 mm²

(10/12 AWG) to 4/2.5/1.5 mm ² (12/14/16 AWG); I _N 32 A			
	light gray	2006-499	25

Modular connector; snaps together; for jumper contact slot

	gray	2004-511	100 (25)
---	------	----------	----------

Test plug adapter; for 4 mm Ø test plug

	gray	2009-174	100 (25)
---	------	----------	----------

Testing tap; for max. 2.5 mm²

	gray	2009-182	100 (25)
---	------	----------	----------