

**Part Number:** SMT-1027-S-R



**Features**

Mounting: Surface Mount  
Frequency: 2700 +/- 500Hz  
This part is RoHS 2002/95/EC Compliant.


**Electrical Specifications**

Operating Voltage	1-2 Vp-p
Rated Current (Max.)	80 mA
Rated Voltage	1.5 Vp-p
Resonant Frequency	27 +/- 500Hz
Sound Pressure Level @ 10 cm (Min.)	85 dBA

Case: LCP  
Weight: 0.8g  
Pin Material: Tin Plated Phosphor Bronze  
Environmentally friendly.


**Mechanical**

*Dimensions are in millimeters, tolerance is ± 0.5 unless otherwise specified.*

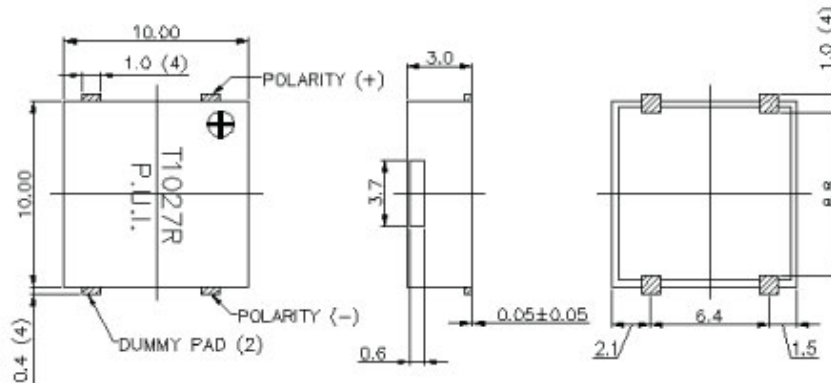

**Performance**

**Typical SPL vs. Frequency**

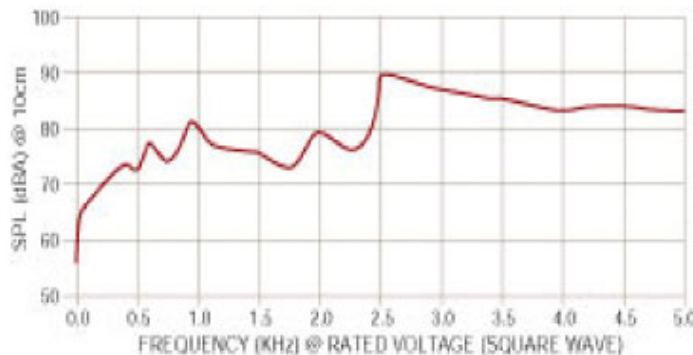

**For application notes and detail drawing specifications, please consult [www.projectsunlimited.com](http://www.projectsunlimited.com).**

Specifications subject to change without notice.

© 2005, Projects Unlimited Inc., All Rights Reserved.