


PXMBNI78FPM04AFL78005 Datasheet



Product Name // 4 Contacts 7/8" Front Panel Mounting
Male 500mm Flying Leads

View Product Page

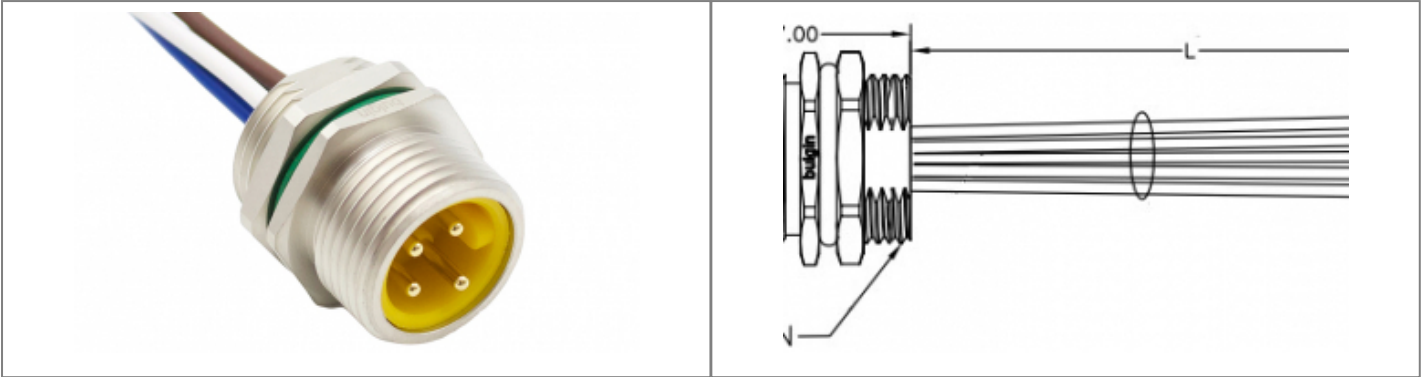

// Product Description:

- 4 Contacts 7-8" Front Panel Mounting Male 0.5M Cable
 - IP67 rated when mated
 - Mechanical Cycles >100
- Operating Temperature -25Â°C to +85Â°C
 - Rated Voltage 300 V
 - ROHS compliance

// General Information:

Product Display Title:	7/8" Front Panel Mounting Male 500mm Flying Leads
Product Family:	Circular Automation Connectors
Product Series:	7/8" Series
Cable Length:	0.5m
Connection Method:	Solder
Contact Type:	Plug Contact
Current Max:	8A
Durability:	>100 Cycles
Function:	Front Panel Mounting Male Connector with Flying Leads
Insulation Resistance:	>100MOhm
Ip Rating:	IP67
Max Operating Temperature:	+80°C
Min Operating Temperature:	-25°C
Number Of Contacts:	4 Contacts
Pin Layout Code:	A Code
Rohs Compliant:	Yes
Thread Size:	7/8-16UN
Voltage Max:	300V

// Product PDF Links



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)