


PXMBNI78FPM05AFL78002 Datasheet



Product Name // 5 Contacts 7/8" Front Panel Mounting
Male 200mm Flying Leads

View Product Page

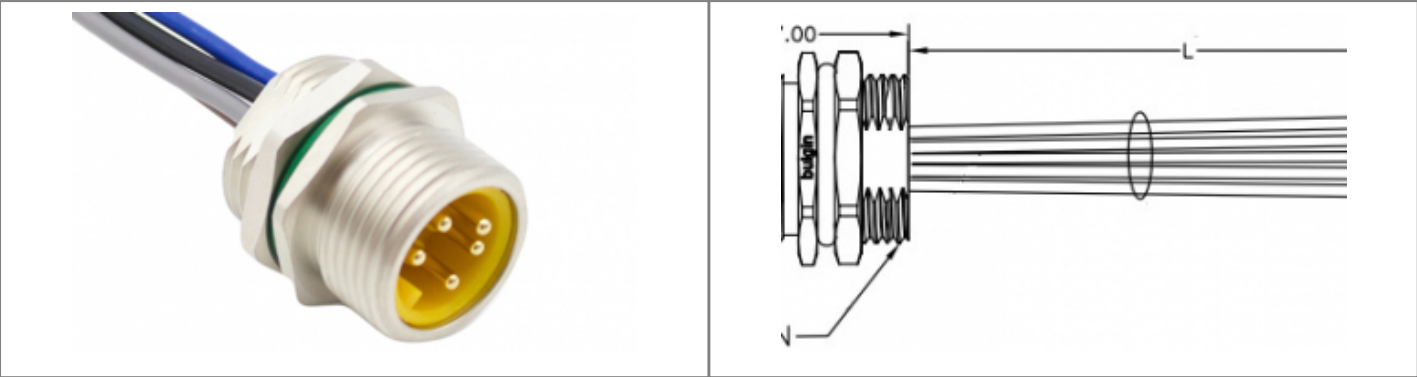

// Product Description:	
5 Contacts 7-8" Front Panel Mounting Male 0.2M Cable	Operating Temperature -25Â°C to +85Â°C
IP67 rated when mated	Rated Voltage 300 V
Mechanical Cycles >100	ROHS compliance

// General Information:	
Product Display Title:	7/8" Front Panel Mounting Male 200mm Flying Leads
Product Family:	Circular Automation Connectors
Product Series:	7/8" Series
Cable Length:	0.2m
Connection Method:	Solder
Contact Type:	Plug Contact
Current Max:	9A
Durability:	>100 Cycles
Function:	Front Panel Mounting Male Connector with Flying Leads
Insulation Resistance:	>100MOhm
Ip Rating:	IP67
Max Operating Temperature:	+80°C
Min Operating Temperature:	-25°C
Number Of Contacts:	5 Contacts
Pin Layout Code:	A Code
Rohs Compliant:	Yes
Thread Size:	7/8-16UN
Voltage Max:	300V

// Product PDF Links

78 Series Circular connectors...