

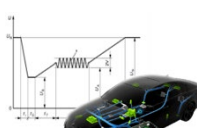



# E36150 Series Bench Power Supply Value Bundles

Save up to 11% with these value bundles

## Step 1

Choose from these eight bundle types that best fits your measurement application.

Bundle model	Bundle components			
	Instrument	Advanced Option	Automotive Option	Advanced PC software
				
1. E36154AGV	<b>E36154A</b> (30V, 80A, 800W)	<b>E36150ADVU</b> (Scope and AWG)	-	-
2. E36155AGV	<b>E36155A</b> (60V, 40A, 800W)	<b>E36150ADVU</b> (Scope and AWG)	-	-
3. E36154AGVX	<b>E36154A</b> (30V, 80A, 800W)	<b>E36150ADVU</b> (Scope and AWG)	<b>E36150ATMU</b> (Automotive features)	-
4. E36155AGVX	<b>E36155A</b> (60V, 40A, 800W)	<b>E36150ADVU</b> (Scope and AWG)	<b>E36150ATMU</b> (Automotive features)	-
5. E36154ABV	<b>E36154A</b> (30V, 80A, 800W)	<b>E36150ADVU</b> (Scope and AWG)	-	CHOOSE either <b>BV9200B</b> OR <b>BV9201B</b>
6. E36155ABV	<b>E36155A</b> (60V, 40A, 800W)	<b>E36150ADVU</b> (Scope and AWG)	-	CHOOSE either <b>BV9200B</b> OR <b>BV9201B</b>
7. E36154ABVX	<b>E36154A</b> (30V, 80A, 800W)	<b>E36150ADVU</b> (Scope and AWG)	<b>E36150ATMU</b> (Automotive features)	CHOOSE either <b>BV9200B</b> OR <b>BV9201B</b>
8. E36155ABVX	<b>E36155A</b> (60V, 40A, 800W)	<b>E36150ADVU</b> (Scope and AWG)	<b>E36150ATMU</b> (Automotive features)	CHOOSE either <b>BV9200B</b> OR <b>BV9201B</b>

## Step 2

Select the AC power cord and input voltage option suitable for your country destination.

### AC power cord

AC power cord	Select your country destination
---------------	---------------------------------

### Input voltage

Option 0E3	AC 230V single-phase 3-wire. 230 VAC +/- 23V operation, 47 to 63 Hz
Option 0E9	AC 100V single-phase 3-wire. 100 VAC +/- 10V operation, 47 to 63 Hz
Option 0EM	AC 115V single-phase 3-wire. 115 VAC +/- 11V operation, 47 to 63 Hz

## Step 3

Select a BenchVue Advanced Power Control and Analysis license. A selection of a license type for either **BV9200B** (up to four instrument connections) or **BV9201B** (single instrument connection) is MANDATORY for the better value bundles **E36154ABV**, **E36155ABV**, **E36154ABVX** and **E36155ABVX**.

BenchVue advanced power control and analysis	License term	License type	Subscription duration
BV9200B	Subscription	Select a license type option: <ul style="list-style-type: none"><li>• Node-locked</li><li>• Floating</li><li>• Transportable</li><li>• USB portable</li></ul>	Select a duration option: <ul style="list-style-type: none"><li>• 6 months</li><li>• 12 months</li><li>• 24 months</li><li>• 36 months</li></ul>
BV9201B	Subscription	Select a license type option: <ul style="list-style-type: none"><li>• Node-locked</li><li>• Floating</li><li>• Transportable</li><li>• USB portable</li></ul>	Select a duration option: <ul style="list-style-type: none"><li>• 6 months</li><li>• 12 months</li><li>• 24 months</li><li>• 36 months</li></ul>

## Step 4

Additional available options can be added and ordered together with the bundles.

### Additional available options

Option SEC	NISPOM and file security (pre-installed)
Option UK6	Commercial calibration certificate with test date
Option 1A7	ISO17025 cal with uncertainty
E363GPBU	GPIB interface module (user installable)

## Step 5

Additional available services and support options can be added and ordered together with the bundles.

#### Additional services and support options

R-55D-001-5ZU	KeysightCare technical support – Upgrade to 5 years
R-51B-001-5Z	Extended warranty – return to Keysight – 5 years
R-50C-011-3	Calibration plan – return to Keysight – 3 years
R-50C-011-5	Calibration plan – return to Keysight – 5 years

## Pricing and quotation

- All of the bundles have already pre-selected the **E36150ADVU** upgrade option. The **E36150ADVU** price is included and already summed in the bundle top model price (see Figure 1, 2, 3 and 4).
- For the automotive bundles **E36154AGVX**, **E36155AGVX**, **E36154ABVX** and **E36155ABVX**, the **E36150ATMU** upgrade option is already pre-selected and the option price is already summed in the bundle top model price (see Figure 2 and 3).
- For the good value bundles **E36154AGV**, **E36155AGV**, **E36154AGVX** and **E36155AGVX**, a discount price of up to \$300 or around 6% is already structured into the bundles top model pricings (see Figure 1 and 2).
- For the better value bundles **E36154ABV**, **E36155ABV**, **E36154ABVX** and **E36155ABVX**, a discount price of up to \$650 or around 11% is already structured into the bundles top model pricings. Please follow **Step 3** to choose a BenchVue Advance Software license type that fits your measurement application. A selection of a license type for either BV9200B or BV9201B is mandatory for the better value bundles and the license price will be rolled up into the total price (see Figure 3 and 4).
- For any additional selection of the available options in **Step 4** and available services and support options in **Step 5**, the prices are individually listed and will be summed into the final price (see Figure 4).

## Packaging

Each bundle will be packaged into a single box and shipped from the factory with a label indicating the bundle product number and contents. Note that products included in each bundle must NOT be broken out and sold separately.

## Point-of-Sale (POS) reporting

Distributors will report the list of product part numbers including the selected options (if applicable) with its associated selling prices on the POS (e.g., E36154ABV, E36155A-SEC, E363GPBU, R-51B-001-5Z, R-55D-001-5ZU, etc.).

## For more information

To learn more about Keysight E36150 Series Value Bundles, visit:

[www.keysight.com/find/E36150bundle](http://www.keysight.com/find/E36150bundle)

To learn more about Keysight E36150 Series, visit: [www.keysight.com/find/E36150](http://www.keysight.com/find/E36150)

To learn more about BV9201B, visit: [www.keysight.com/find/BV9201B](http://www.keysight.com/find/BV9201B)



Keysight enables innovators to push the boundaries of engineering by quickly solving design, emulation, and test challenges to create the best product experiences. Start your innovation journey at [www.keysight.com](http://www.keysight.com).

This information is subject to change without notice. © Keysight Technologies, 2023, Published in USA, October 16, 2023, 3123-1048.EN