
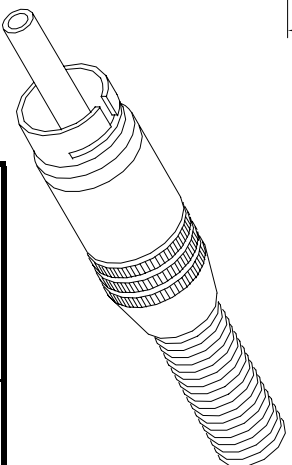


- A range of high quality UK manufactured phono plugs made from machined brass with various plating options.
- Centre contact available in hollow tube.
- Ground contact with unique 'T' shape slot for maximum contact area.
- Internal cable clamp for secure cable connection.
- Spring strain relief.
- Colour coded ID rings for easy cable identification.
- Attractive body styling.
- Maximum cable size 5.5mm

Rating – 5A at 200 Vdc/150 Vac max.
 Insulation resistance – 100M Ω at 500 Vdc

Dimensions

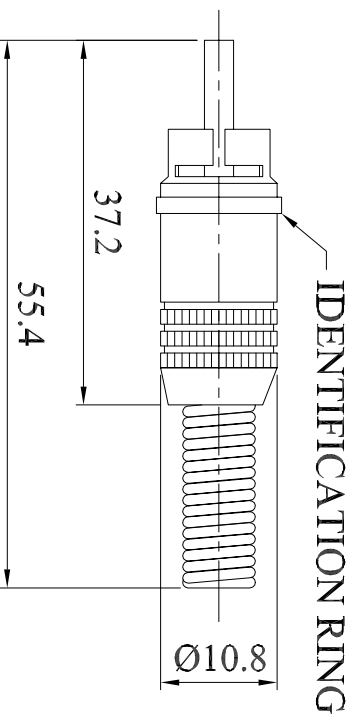

- Material : Brass, flash gold plated
- Centre contact : Brass, flash gold plated
- Ground contact : Brass, flash gold plated
- Insulation : Noryl SE1
- Cable clamp : Brass, flash gold plated
- Spring : Spring steel, black chrome plated
- Cap : Brass, black chrome plated

Deltron Part No.	Description
332-0000	FLASH GOLD PLUG ASSY/BLACK CHROME CAP & SPRING
332-0100	FLASH GOLD PLUG ASSY/BLACK CHROME CAP & SPRING (BLACK ID RING)
332-0200	FLASH GOLD PLUG ASSY/BLACK CHROME CAP & SPRING (BLUE ID RING)
332-0500	FLASH GOLD PLUG ASSY/BLACK CHROME CAP & SPRING (RED ID RING)
332-0600	FLASH GOLD PLUG ASSY/BLACK CHROME CAP & SPRING (WHITE ID RING)
332-0700	FLASH GOLD PLUG ASSY/BLACK CHROME CAP & SPRING (YELLOW ID RING)

CONVERTED FROM PS0356 ISS2 (04.01.94) IN JAN 2003

Drgn No 332 SERIES TITLE PROFESSIONAL PHONO LINE PLUG

ALL DIMENSIONS IN MM
 ANGLES IN DECIMAL DEGREES



DELTRON Components

ISS 2

GENERAL SPECIFICATION FOR 332 SERIES

CUSTOMER

Aprvd Date 31/01/03

Aprvd By MC

Drwn by BS

Scale: NTS

Sheet 1 / 1