

# 15V DC 1A 15W Power Supply




## Part TP1207

### Features:

- Compact Size (71.9 x 41.3 x 24.7mm)
- Short circuit, over current and input protection
- RoHS compliant
- Safety Approved to UL, CE, UKCA, SAA, CB
- Wide range 100 – 240vac input for World use
- DC Cable length 1.5 metres
- Terminated with a 2.1 x 5.5 x 12mm industry standard connector
- Polarity +ve centre



Input voltage (& Inrush Current)	90 – 264vac 47 – 63hz (40 amps max.)
Short Circuit Protection	3.6A Integrated fuse
Ripple & Noise	120mV p – p max.
Efficiency	DOE VI (Level VI)
Leakage Current	0.25mA max.
Standby Power	0.1W max.
Operating Temperature	0°C~40°C
Storage Temperature	-20°C~+ 70°C

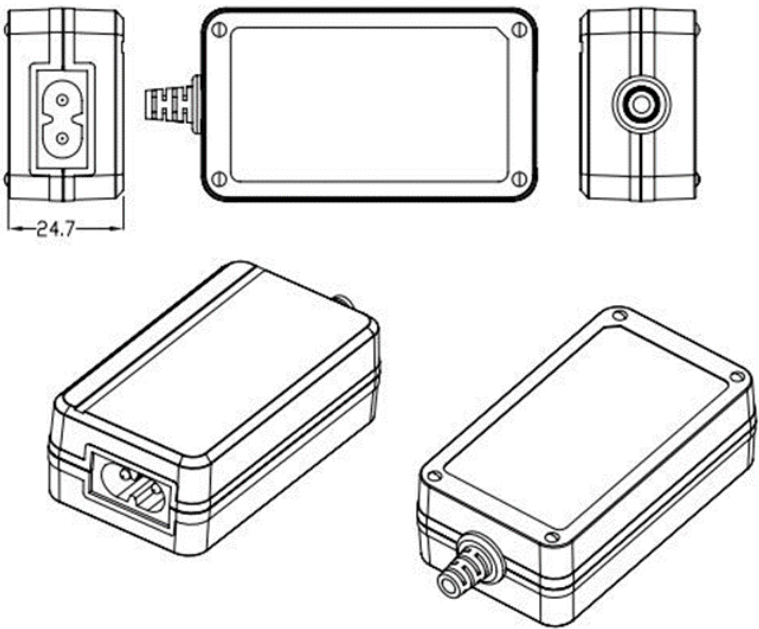

This specification is not for general release or circulation. Tiger Power reserves the right to make changes to spec. or product without notice or liability.

### TIGER POWER PRODUCTS – QUALITY & RELIABILITY