 




Order Code	TCK-185
Inductance (each winding)	415 μ H \pm 35% (at 100 kHz / 100 mV)
Impedance (DCR)	5 m Ω max.
Rated Current	16 A max.
Operating Temperature	-40°C to +125°C
RoHS Exemptions	No Exemptions



Impedance Curve

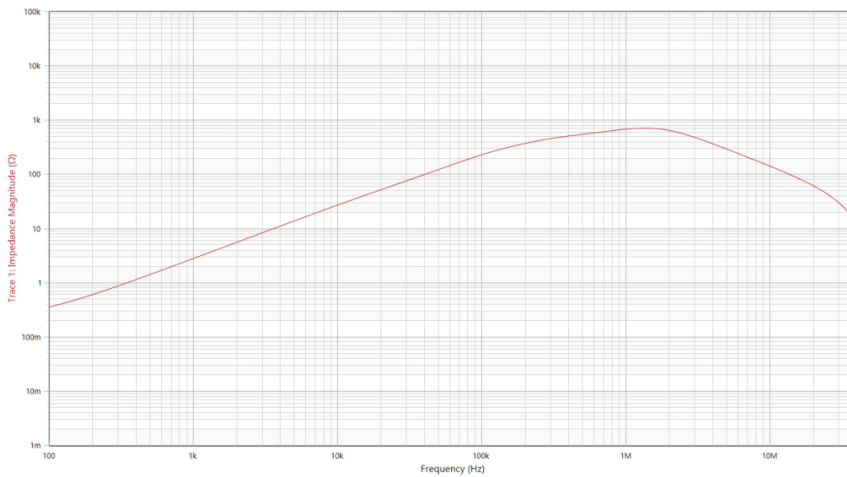

Outline Dimensions

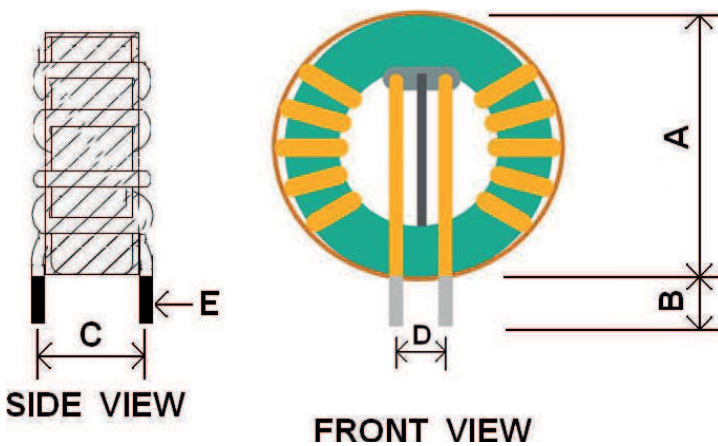

Dimensions [mm]	
A	14.45 max.
B	5.0 \pm 2
C	10.0 \pm 1
D	4.0 \pm 1
E	\varnothing 1.0 \pm 1

All specifications valid at +25°C, unless otherwise stated.