

DL5 LED DOWNLIGHT

5W

Easy installation



**3
YEAR
WARRANTY**
WITH ONLINE
REGISTRATION

Alternative Bezels
Available



BLACK
[230069]



BRASS
[230038]



BRUSHED STEEL
[230045]



CHROME
[230052]




DIMMABLE



FIRE RATED
BS476-21

30/60/90
minutes

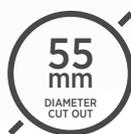

55
mm
DIAMETER
CUT OUT



IP65
RATED

With Bezel

FEATURES:

- Comes with white bezel as standard - others available.
- Easy to install with 55mm cutout
- Easily switch bezels after installation

APPLICATIONS



BATH &
SHOWER



COMMERCIAL



EDUCATION



HOME &
RESIDENTIAL



LOBBIES &
CORRIDORS



OFFICES




RETAIL

5W

DL5 LED DOWNLIGHT

Easy installation

Part No.	230007	230014	230021
Part No. Emergency Version	230007E	230014E	230021E
DESCRIPTION	5W DL5 Downlight	5W DL5 Downlight	5W DL5 Downlight
DIMENSIONS	52 x 80Ø x 51mm depth		
CUTOUT	55mm Ø		
POWER CONSUMPTION	5kWh/1000hrs		
POWER FACTOR	0.85		
COLOUR TEMPERATURE	3000K (Warm White)	4000K (Cool White)	6000K (Daylight)
COLOUR RENDITION (CRI)	Ra>80		
LUMENS	500lm	560lm	530lm
DIMMABLE	Yes		
IK RATING	BS476-21 30/60/90		
IP RATING	IP65 Bezel Only		
BEAM ANGLE	40°		
POWER CONSUMPTION	5kWh/1000hrs		
POWER FACTOR	0.85		
WORKING TEMPERATURES	-30°C to +40°C		
CONSTRUCTION	Aluminum / Plastic IP65 (Bezel only)		
FIRE RESISTANT	BS476-21 30/60/90mins		
CERTIFICATION	CE, RoHS		
ENERGY CONSUMPTION (EC)	5kWh/1000hrs		
WARRANTY	1 year (+ 2 years extended warranty with online registration)		
BUILDING REGS	Yes		

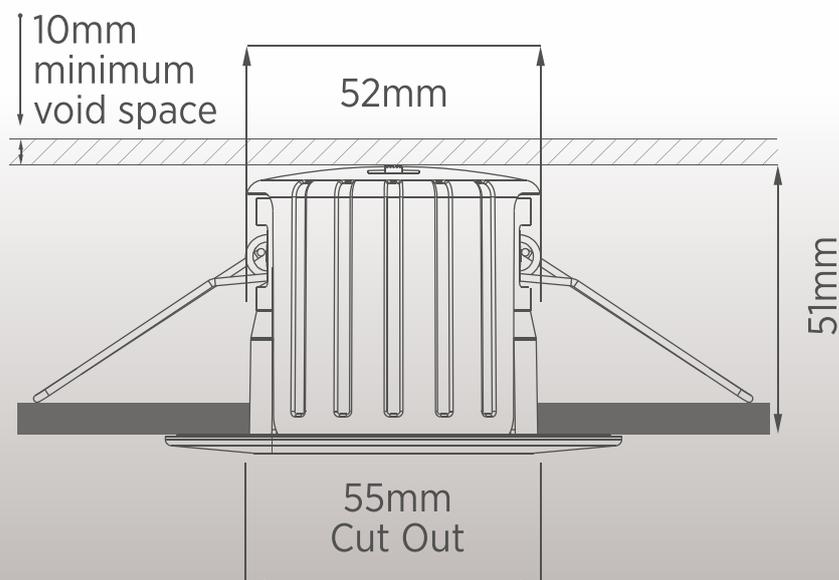

BRIGHT SOURCE



Formerly rated A+
(same quality,
new energy rating
label regulations)

