




ODD JOB SERIES

ALUMINIUM WORK PLATFORMS

**LIGHTWEIGHT
& STRONG**

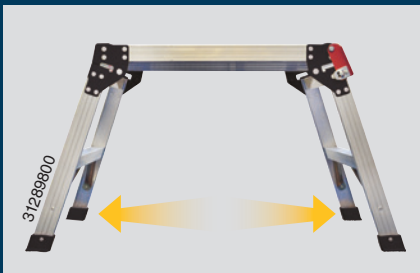

Splayed base for
extra stability


PERFECT TOOL TO GIVE YOU A BOOST FOR ANY ODD JOB



Locking hinges
for added safety



Non-slip platform for comfort
and security

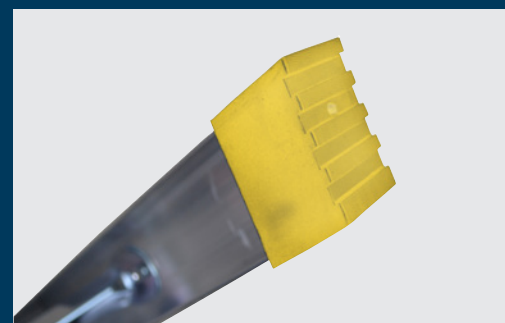

Slip-resistant feet
for added stability

150kg

MAX. LOAD

(Load includes user, tools, materials, etc.)



- The perfect tool for giving you a boost for odd jobs on the job site
- Lightweight design which makes the Odd Job easy to carry around
- Compact folded dimensions for easy storage

SPECIFICATIONS

Product Code	Style	Folded Dimensions	Platform Size	Platform Height	Safe Working Height*	Weight
31089818	Odd Job	0.39m x 0.70m x 0.15m (1'3" x 2'4" x 6")	0.30m x 0.60m (1' x 1'11")	0.50m (1'8")	2.25m (7'5")	3.7kg
31289800	Odd Job 600	0.70m x 0.62m x 0.18m (2'4" x 2' x 7")	0.60m x 0.60m (1'11" x 1'11")	0.50m (1'8")	2.25m (7'5")	5.7kg

*Based on 1.75m (5'9") as the average reach height of a person.

Large platform provides a non-slip work surface



Slip-resistant feet for added stability

Splayed base for extra stability



Simple and safe to use with locking hinges for added safety whilst working

Square platform ideal for those needing a large space whilst working



SAFETY TESTED

Suitable for Trade use.