



714SERIES

MasterTrade™ STEPLADDER

**BUILT TO
LAST**



Engineered using high-grade aluminum, suitable for even the toughest tasks on a job site.



A TRADITIONAL LINE OF LADDERS ENGINEERED WITH PROGRESSIVE THINKING



Slip-resistant treads
for comfort and security



Heavy-duty spreaders
for ease of stowage



Slip-resistant feet
for maximum stability



714SERIES

MasterTrade™ STEPLADDER

150kg

MAX. LOAD

(Load includes user, tools, materials, etc.)




- Made from high grade aluminium, exceptionally robust and built to last
- Box section stiles for maximum strength, yet lightweight to use

SPECIFICATIONS

Product Code	No. of Treads	Open Height	Safe Working Height*	Weight
7140418	4	0.85m (2'9")	1.97m (6'5")	3.88kg
7140518	5	1.06m (3'5")	2.18m (7'1")	4.64kg
7140618	6	1.27m (4'2")	2.39m (7'10")	5.55kg
7140818	8	1.69m (5'6")	2.81m (9'2")	7.29kg
7141018	10	2.11m (6'11")	3.23m (10'7")	9.46kg
7141218	12	2.53m (8'3")	3.65m (11'11")	11.70kg

*Based on 1.75m (5'9") as the average reach height of a person.

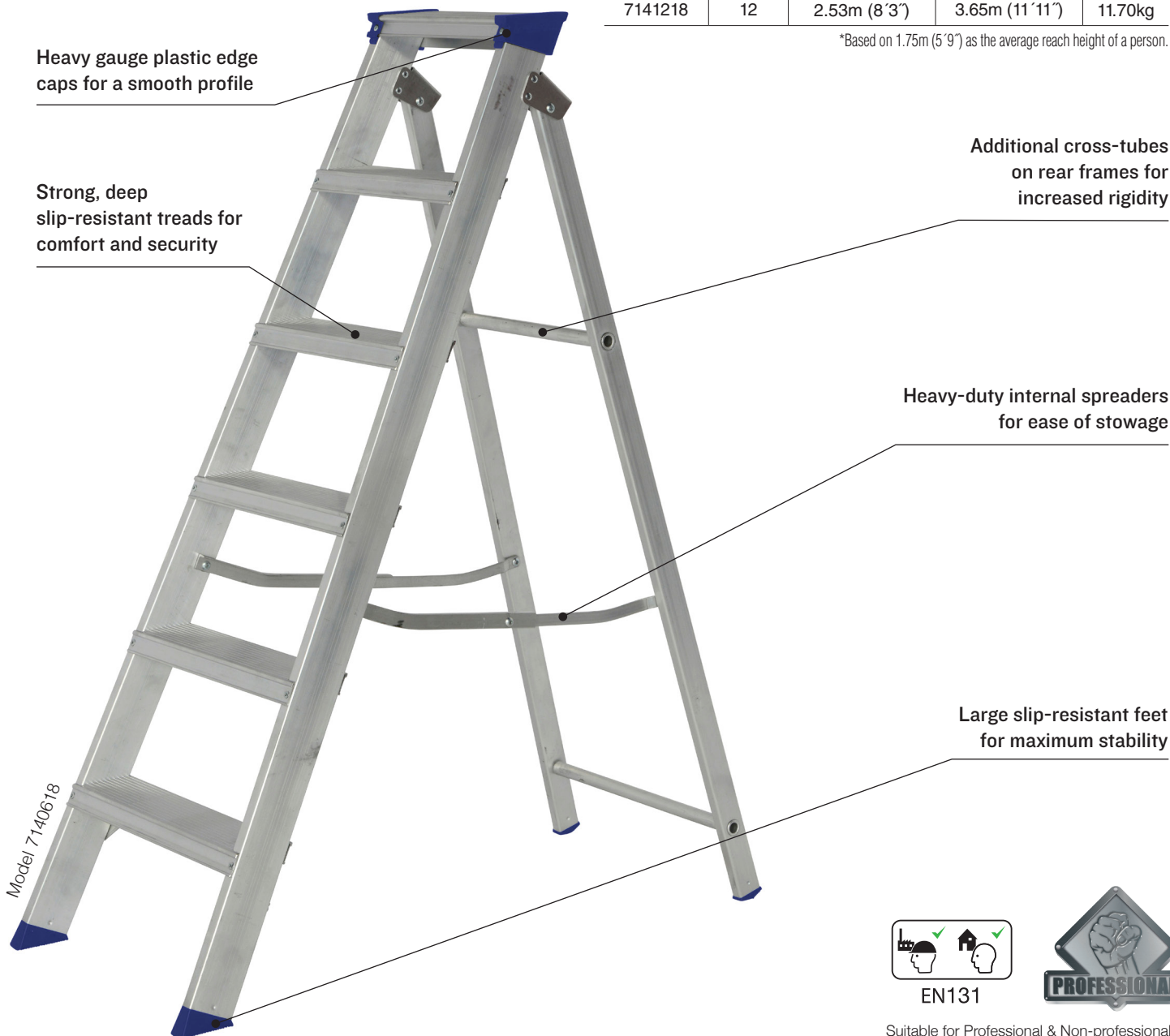

EN131



Suitable for Professional & Non-professional use