




# 715SERIES

## MasterTrade™ PLATFORM LADDER

**EXTRA-STRONG  
PLATFORM**

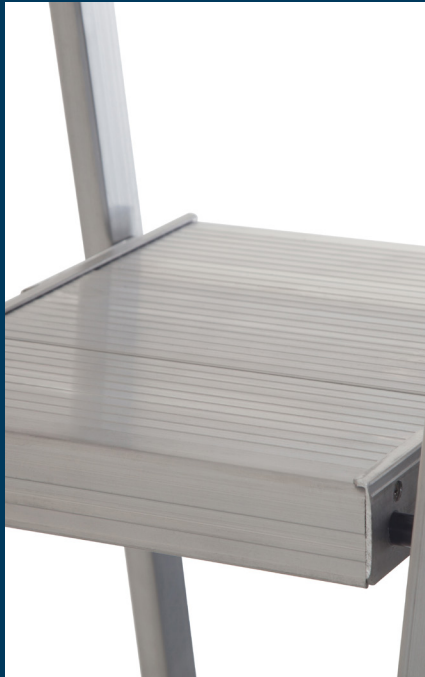

Cycle tested to over  
50,000 cycles



**A TRADITIONAL LINE OF LADDERS ENGINEERED WITH PROGRESSIVE THINKING**



Slip-resistant treads  
for comfort and security



Heavy-duty spreaders  
for ease of stowage



Slip-resistant feet  
for maximum stability





# 715SERIES

## MasterTrade™ PLATFORM LADDER

# 150kg

MAX. LOAD

(Load includes user, tools, materials, etc.)



- Made from high grade aluminium, exceptionally robust and built to last
- Box section stiles for maximum strength, yet lightweight to use

### SPECIFICATIONS

Product Code	No. of Treads	Platform Height	Safe Working Height*	Weight
7150418	4	0.85m (2'9")	2.60m (8'6")	6.65kg
7150618	6	1.27m (4'2")	3.02m (9'11")	8.60kg
7150818	8	1.69m (5'6")	3.44m (11'3")	10.78kg
7151018	10	2.11m (6'11")	3.86m (12'8")	12.98kg
7151218	12	2.53m (8'3")	4.28m (14')	15.25kg

\*Based on 1.75m (5'9") as the average reach height of a person.



Heavy gauge plastic edge caps for a smooth profile

Extended support rail for greater user comfort and utility

Strong, deep slip-resistant treads for comfort and security

Large slip-resistant standing platform to provide secure and comfortable work area

Heavy-duty internal spreaders for ease of stowage

Additional cross-tubes on rear frames for increased rigidity

Large slip-resistant feet for maximum stability



EN131



Suitable for Professional & Non-professional use