



Model No. 640EURD

40mm wide nickel plated solid brass padlock

Best Used For:



Residential Gates & Fences



Sheds, Workshops & Garages



Self-Storage Units & Lockers



Tools, Job Boxes & Gang Boxes

Security Level:



Basic to medium security:

Generally recommended for indoor general purpose

Overview & Features

Product Features


- 40mm wide nickel plated solid brass body for strength, durability and corrosion resistance
- Stainless steel shackle for maximum resistance to corrosion
- 5-pin cylinder
- Dual locking levers provide extra pry resistance
- Limited Lifetime Warranty

Product Details

The Master Lock No. 640EURD Weather Resistant Padlock features a 40mm wide nickel plated solid brass body for maximum strength, reliability and corrosion resistance. The 6mm diameter shackle is 22mm long and made of nickel-plated steel, offering resistance to harsh outdoor conditions. The 5-pin cylinder prevents picking and the dual locking levers provide resistance against prying and hammering. The Limited Lifetime Warranty provides peace of mind from a brand you can trust.

Product Specifications

Product Number	640EURD
Body Width	40mm
Shackle Dimensions	A: 6mm B: 22mm C: 19mm
Colour	Silver
Description	Keyed Different
Shelf Pack Qty	6
Master Carton Qty	24

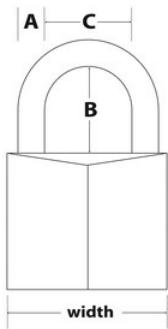

Master Lock Europe S.A.S.

10 avenue de l'arche - Le Colisée Gardens, bâtiment A - 92 400 Courbevoie - La Défense - France
O:+33-1-41437200 | F:+33-1-41437204
www.masterlock.eu